

T-Series Horizontal Sleeve, Side Fill



The side fill horizontal T-Series sleeve has vent holes located 90 degrees from the tap hole to facilitate side fill installations when the interferences of the structure will not allow top filling. Vent holes are added to horizontal sleeves to reduce air entrapment and help ensure proper filling of the sleeve.

功能

Designed to connect horizontal reinforcing bars and angular reinforcing bars up to 45 degrees

Used to splice the same diameter bars

Works with saw cut, flame cut and sheared bars

Can be visually inspected after installation

Available with extended sleeve lengths

技术参数

完成: 普通

材料: 钢

100% 美国国内内容: 是

Table 1/2

物料号	套管	钢筋尺寸, 公制	钢筋尺寸, 美国	钢筋尺寸, 加拿大	直径 1 (Ø1)	直径 2 (Ø2)
RBT6101HSA	标准长度	20 mm	#6	20M	38 mm	25 mm
RBT7101HSA	标准长度	22 mm	#7		41 mm	29 mm
RBT1091HSA	标准长度	32 mm	#10		57 mm	41 mm

物料号	套管	钢筋尺寸，公制	钢筋尺寸，美国	钢筋尺寸，加拿大	直径 1 (Ø1)	直径 2 (Ø2)
RBT11101HSA	标准长度	36 mm	#11	35M	64 mm	44 mm
RBT81011HSA	加长长度	25 mm	#8	25M	48 mm	32 mm
RBT8101HSA	标准长度	25 mm	#8	25M	48 mm	32 mm
RBT9101HSA	标准长度	28 mm	#9	30M	54 mm	38 mm
RBT111011HSA	加长长度	36 mm	#11	35M	64 mm	44 mm
RBT14101HSA	标准长度	43 mm	#14	45M	76 mm	54 mm
RBT1891HSA	标准长度	57 mm	#18	55M	95 mm	67 mm

Table 2/2				
物料号	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	单位重量
RBT6101HSA	127 mm	64 mm	20mm	0.63 kg
RBT7101HSA	127 mm	64 mm	20mm	0.69 kg
RBT1091HSA	140 mm	70 mm	20mm	1.34 kg
RBT11101HSA	152 mm	76 mm	20mm	1.93 kg
RBT81011HSA	152 mm	76 mm	20mm	1.38 kg
RBT8101HSA	127 mm	64 mm	20mm	0.98 kg
RBT9101HSA	127 mm	64 mm	20mm	1.14 kg
RBT111011HSA	178 mm	89 mm	26mm	2.25 kg


物料号	长度 1 (L1)	长度 2 (L2)	长度 3 (L3)	单位重量
RBT14101HSA	178 mm	89 mm	26mm	3.17 kg
RBT1891HSA	229 mm	114 mm	26mm	6.51 kg

其他产品详情

Prior to installation, please read and understand all of the detailed instructions and safety notices provided in the nVent LENTON Cadweld Rebar Splicing System Instruction Manual.

Sizes not shown may be available by special order. Contact your nVent LENTON representative for more information.

图

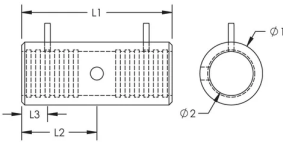

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

北美	欧洲	欧洲	亚太地区
+1.800.753.9221	荷兰：	德国：	上海：
，按 1 转客户服务	+31 800-0200135	800 1890272	+ 86 21 2412 1618/19
，按 2 转技术支持	法国：	其他国家/地区：	悉尼：
	+33 800 901 793	+31 13 5835404	+61 2 9751 8500



我们强大的品牌组合：

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE