


# Front Panel Alternative for Combined Mounting, U-profile, Textile, 6 U, 2 HP

## Power Utilities

### 物料号

**30849-140**

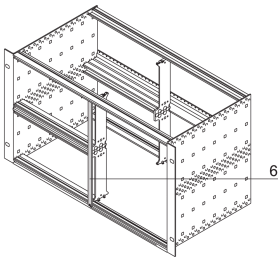

The 2 HP wide front panel covers an open slot. The U-profile front panel can be combined with a textile EMC gasket. It be fixed with screws and washers. Due to the 2 HP width no sleeves can be used.

### 认证



### 功能

U-profile front panel 6 U, 2 HP, Al, 2.5 mm

Prepared for textile EMC gasket

### 产品属性

产品类型: 前面板

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

机架高度: 6 U

包装数量: 5

## 其他产品详情

---

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

## 警告

---

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



我们强大的品牌组合:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**