


Novastar 钢制网孔门

电力公用事业

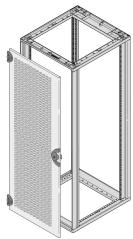

网孔门可实现 60 % 的通风率，从而提供更好的被动冷却效果。Novastar网孔门可实现 180° 开门，外表美观大方。

认证



功能

可以在前后安装

Perforated (60 % ventilation opening)

Opening angle 180°

配钥匙的锁 (2233X)

技术参数

Table 1/2

物料号	机架高度	高度	宽度	颜色	色号	产品类型
25230-081	6 U	288.4 mm	553 mm	暗灰色	RAL 7021	机柜门

物料号	机架高度	高度	宽度	颜色	色号	产品类型
26230-081	6 U	288.4 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-082	9 U	421.75 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-082	9 U	421.75 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-083	12 U	555.1 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-083	12 U	555.1 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-084	16 U	732.9 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-084	16 U	732.9 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-085	20 U	910.7 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-085	20 U	910.7 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-086	25 U	1132.95 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-086	25 U	1132.95 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-091	29 U	1310.75 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-091	29 U	1310.75 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-087	34 U	1533 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-087	34 U	1533 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-088	38 U	1710.8 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-088	38 U	1710.8 mm	553 mm	浅灰色	RAL 7035	机柜门

物料号	机架高度	高度	宽度	颜色	色号	产品类型
25230-089	43 U	1933.05 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-089	43 U	1933.05 mm	553 mm	浅灰色	RAL 7035	机柜门
25230-090	47 U	2110.85 mm	553 mm	暗灰色	RAL 7021	机柜门
26230-090	47 U	2110.85 mm	553 mm	浅灰色	RAL 7035	机柜门

Table 2/2

物料号	类型
25230-081	Steel Door, Perforated
26230-081	Steel Door, Perforated
25230-082	Steel Door, Perforated
26230-082	Steel Door, Perforated
25230-083	Steel Door, Perforated
26230-083	Steel Door, Perforated
25230-084	Steel Door, Perforated
26230-084	Steel Door, Perforated
25230-085	Steel Door, Perforated
26230-085	Steel Door, Perforated
25230-086	Steel Door, Perforated

物料号	类型
26230-086	Steel Door, Perforated
25230-091	Steel Door, Perforated
26230-091	Steel Door, Perforated
25230-087	Steel Door, Perforated
26230-087	Steel Door, Perforated
25230-088	Steel Door, Perforated
26230-088	Steel Door, Perforated
25230-089	Steel Door, Perforated
26230-089	Steel Door, Perforated
25230-090	Steel Door, Perforated
26230-090	Steel Door, Perforated

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE