


19" 恒温器前面板，带数字显示屏，1 U

19" 恒温器前面板，带数字显示屏，1 U

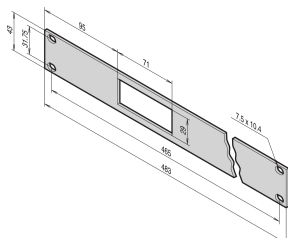

认证



功能

19 英寸前面板, 1 U, 恒温器开孔，带数字显示屏

技术参数

附件类型: 前面板

Table 1/3

物料号	类型	安装	EMC 屏蔽	材料	正面表面处理	反面表面处理
30118-360	19" 前面板	正面螺钉安装	否	铝	涂漆	涂漆
30118-267	19" 前面板	正面螺钉安装	否	铝	阳极氧化	阳极氧化
30118-315	19" 前面板	正面螺钉安装	否	铝	涂漆	涂漆

Table 2/3

物料号	颜色代码	机架高度	高度	机架宽度	宽度	深度
-----	------	------	----	------	----	----

30118-360	RAL 7021	1U	43mm	95HP	483mm	3mm
30118-267		1U	35mm		76mm	3mm
30118-315	RAL 7035	1U	43mm	95HP	483mm	3mm

Table 3/3			
物料号	包装数量	完成	快速发货
30118-360	1	粉末涂层	No
30118-267	1	阳极氧化	No
30118-315	1	粉末涂层	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE