

19 英寸前面板

前面板为阳极氧化铝材质.



认证



功能

铝，厚度 4 或 3 毫米，阳极氧化或涂漆

技术参数

机架宽度: 95HP
材料: 铝
附件类型: 前面板
产品类型: 前面板

Table 1/3

物料号	机架高度	深度 (D)	安装	完成	正面表面处理	包装数量
30118-948	1U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-299	1U	3mm	正面螺钉安装	粉末涂层	涂漆	1

物料号	机架高度	深度 (D)	安装	完成	正面表面处理	包装数量
30219-098	1U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-074	1U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-950	3U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-302	3U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-104	3U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-076	3U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-951	4U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-303	4U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-107	4U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-077	4U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-953	6U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-305	6U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-113	6U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-079	6U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-954	7U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-306	7U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-137	7U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1

物料号	机架高度	深度 (D)	安装	完成	正面表面处理	包装数量
40304-080	7U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-956	9U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-308	9U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-143	9U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-082	9U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
30118-301	2U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-304	5U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-307	8U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-309	10U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-949	2U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-952	5U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-955	8U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30118-957	10U	3mm	正面螺钉安装	粉末涂层	涂漆	1
30219-101	2U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
30219-110	5U	3mm	正面螺钉安装	粉末涂层	阳极氧化	1
30219-138	8U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1
30219-144	10U	3mm	正面螺钉安装	阳极氧化	阳极氧化	1

物料号	机架高度	深度 (D)	安装	完成	正面表面处理	包装数量
40304-075	2U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-078	5U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-081	8U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1
40304-083	10U	4mm	正面螺钉安装	阳极氧化	阳极氧化	1

Table 2/3

物料号	反面表面处理	边缘处理	颜色代码	EMC 屏蔽	高度 (H)	类型
30118-948	涂漆		RAL 7021	否	43.6mm	19" 前面板
30118-299	涂漆		RAL 7035	否	43.6mm	19" 前面板
30219-098	阳极氧化	否		否	43.6mm	19" 前面板
40304-074	阳极氧化	是		否	43.6mm	19" 前面板
30118-950	涂漆		RAL 7021	否	132.5mm	19" 前面板
30118-302	涂漆		RAL 7035	否	132.5mm	19" 前面板
30219-104	阳极氧化	否		否	132.5mm	19" 前面板
40304-076	阳极氧化	是		否	132.5mm	19" 前面板
30118-951	涂漆		RAL 7021	否	177mm	19" 前面板
30118-303	涂漆		RAL 7035	否	177mm	19" 前面板
30219-107	阳极氧化	否		否	177mm	19" 前面板

物料号	反面表面处理	边缘处理	颜色代码	EMC 屏蔽	高度 (H)	类型
40304-077	阳极氧化	是		否	177mm	19" 前面板
30118-953	涂漆		RAL 7021	否	265.9mm	19" 前面板
30118-305	涂漆		RAL 7035	否	265.9mm	19" 前面板
30219-113	阳极氧化	否		否	265.9mm	19" 前面板
40304-079	阳极氧化	是		否	265.9mm	19" 前面板
30118-954	涂漆		RAL 7021	否	310.3mm	19" 前面板
30118-306	涂漆		RAL 7035	否	310.3mm	19" 前面板
30219-137	阳极氧化	否		否	310.3mm	19" 前面板
40304-080	阳极氧化	是		否	310.3mm	19" 前面板
30118-956	涂漆		RAL 7021	否	399.2mm	19" 前面板
30118-308	涂漆		RAL 7035	否	399.2mm	19" 前面板
30219-143	阳极氧化	否		否	399.2mm	19" 前面板
40304-082	阳极氧化	是		否	399.2mm	19" 前面板
30118-301	涂漆		RAL 7035	否	88.1mm	19" 前面板
30118-304	涂漆		RAL 7035	否	221.4mm	19" 前面板
30118-307	涂漆		RAL 7035	否	354.8mm	19" 前面板
30118-309	涂漆		RAL 7035	否	443.7mm	19" 前面板

物料号	反面表面处理	边缘处理	颜色代码	EMC 屏蔽	高度 (H)	类型
30118-949	涂漆		RAL 7021	否	88.1mm	19" 前面板
30118-952	涂漆		RAL 7021	否	221.4mm	19" 前面板
30118-955	涂漆		RAL 7021	否	354.8mm	19" 前面板
30118-957	涂漆		RAL 7021	否	443.7mm	19" 前面板
30219-101	阳极氧化	否		否	88.1mm	19" 前面板
30219-110	阳极氧化	否		否	221.4mm	19" 前面板
30219-138	阳极氧化	否		否	354.8mm	19" 前面板
30219-144	阳极氧化	否		否	443.7mm	19" 前面板
40304-075	阳极氧化	是		否	88.1mm	19" 前面板
40304-078	阳极氧化	是		否	221.4mm	19" 前面板
40304-081	阳极氧化	是		否	354.8mm	19" 前面板
40304-083	阳极氧化	是		否	443.7mm	19" 前面板

Table 3/3		
物料号	宽度 (W)	快速发货
30118-948	483mm	No
30118-299	483mm	No
30219-098	483mm	No

物料号	宽度 (W)	快速发货
40304-074	483mm	No
30118-950	483mm	No
30118-302	483mm	No
30219-104	483mm	No
40304-076	483mm	No
30118-951	483mm	No
30118-303	483mm	No
30219-107	483mm	No
40304-077	483mm	No
30118-953	483mm	No
30118-305	483mm	No
30219-113	483mm	No
40304-079	483mm	No
30118-954	483mm	No
30118-306	483mm	No
30219-137	483mm	No
40304-080	483mm	No


物料号	宽度 (W)	快速发货
30118-956	483mm	No
30118-308	483mm	No
30219-143	483mm	No
40304-082	483mm	No
30118-301	483mm	No
30118-304	483mm	No
30118-307	483mm	No
30118-309	483mm	No
30118-949	483mm	No
30118-952	483mm	No
30118-955	483mm	No
30118-957	483mm	No
30219-101	483mm	No
30219-110	483mm	No
30219-138	483mm	No
30219-144	483mm	No
40304-075	483mm	No

物料号	宽度 (W)	快速发货
40304-078	483mm	No
40304-081	483mm	No
40304-083	483mm	No

其他产品详情

请单独订购 19" 装配套件。

图

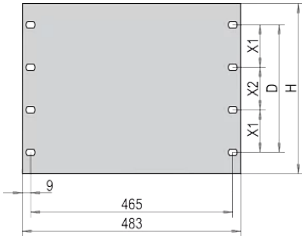

警告

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE