


空气挡板, 前面板, 经过升级获得更高电磁屏蔽性, 碳钢

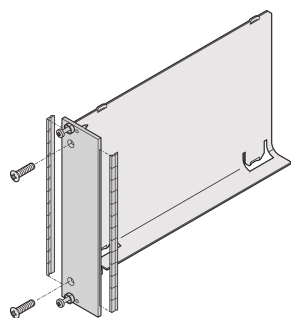

带扁平前面板的空气挡板可以覆盖空插槽，防止空气向外泄漏。扁平前面板可以采用不锈钢 EMC 垫片。

认证



功能

空气挡板可避免空插槽空气向外泄漏

安装方式，按压上盖推入到导轨中

技术参数

产品类型: 空气挡板

材料: 铝

完成: 阳极氧化; 钝化

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

类型: 带前面板

Table 1/2

物料号	机架高度	包装数量	深度	EMC 屏蔽	机架宽度	搭配
-----	------	------	----	--------	------	----

20848-712	3U	1	160mm	无（可改装）	4HP	插箱, 仪器箱
20848-721	6U	1	220mm	无（可改装）	4HP	插箱, 仪器箱
20848-720	6U	1	160mm	无（可改装）	4HP	插箱, 仪器箱
20848-713	3U	1	220mm	无（可改装）	4HP	插箱, 仪器箱

Table 2/2	
物料号	快速发货
20848-712	No
20848-721	No
20848-720	No
20848-713	No

其他产品详情

可应要求提供适用 280 mm 深度和 80 mm 后部 I/O 板的空气挡板。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE