


# 空气挡板, U 形前面板, 经过升级获得更高电磁屏蔽性, 泡棉

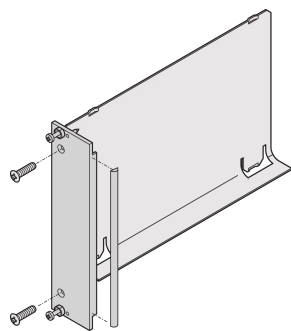

带 U 形前面板的空气挡板可以覆盖空插槽，消除气流出口。U 型前面板可采用纺织 EMC 垫片。

## 认证



## 功能

空气挡板可以防止空插槽漏气

安装方式，按压上盖推入到导轨中

## 技术参数

产品类型: 空气挡板

材料: 铝

完成: 阳极氧化; 钝化

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; Inpac

类型: 带前面板

Table 1/2

| 物料号 | 机架高度 | 包装数量 | 深度 | EMC 屏蔽 | 机架宽度 | 搭配 |
|-----|------|------|----|--------|------|----|
|-----|------|------|----|--------|------|----|

|           |    |   |       |        |     |         |
|-----------|----|---|-------|--------|-----|---------|
| 20848-728 | 3U | 1 | 160mm | 无（可改装） | 4HP | 插箱, 仪器箱 |
| 20848-729 | 3U | 1 | 220mm | 无（可改装） | 4HP | 插箱, 仪器箱 |
| 20848-736 | 6U | 1 | 160mm | 无（可改装） | 4HP | 插箱, 仪器箱 |
| 20848-737 | 6U | 1 | 220mm | 无（可改装） | 4HP | 插箱, 仪器箱 |

| Table 2/2 |      |
|-----------|------|
| 物料号       | 快速发货 |
| 20848-728 | No   |
| 20848-729 | No   |
| 20848-736 | No   |
| 20848-737 | No   |

## 其他产品详情

可应要求提供适用 280 mm 深度和 80 mm 后部 I/O 板的空气挡板。

## 警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

### North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

### Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**