


带固定把手的 AMC 填充模块 ECO

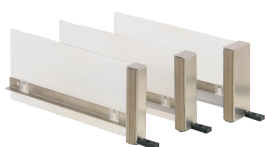

这款 AdvancedMC 填充模块由不带 LED 的不锈钢前面板组成，左侧和底部配有 EMC 垫片。填充模块通过塑料头部装置的卡扣式结构固定在机箱插件导轨中。此模块可用于覆盖空插槽，以确保 EMC 屏蔽效果并关闭前面板，将泄漏的空气密封在机箱中。这些填充模块可用于 AdvancedMC 载板和 MicroTCA 插槽。不需要锁杆。

认证



功能

ECO AdvancedMC 填充模块，头部位置带有简单的卡扣结构，而不是推式把手结构

适用传统, 分立式和混合式载板及 MicroTCA 系统

前面板, 不锈钢

可以使用可选的空气挡板（气流可调节）引导机箱中的气流。

技术参数

产品系列: AdvancedMC

类型: 填充模块

产品类型: 系统模块

Table 1/1

物料号	设计特征	包装数量	材料	快速发货
20849-352	全尺寸	1	不锈钢	No

物料号	设计特征	包装数量	材料	快速发货
20849-351	中尺寸	1	不锈钢	No
20849-353	全尺寸	1	不锈钢	No
20849-350	中尺寸	1	不锈钢	No

其他产品详情

不能使用微型开关。

请单独订购空气挡板。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE