


带拉杆把手的 AMC 前面板

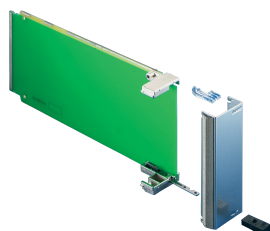

AdvancedMC 前面板，适用符合 AMC.0 2.0 修订版标准的模块，含EMC 垫片。

认证



功能

符合 AMC.0 R2.0 技术参数

前面板，支持拉杆机构（开孔可安装发光管）

适合与 AMC 拉杆把手机构配合使用, AMC.0 R2.0

技术参数

附件类型: 前面板

产品类型: 前面板


Table 1/2

物料号	高度 (H)	机架宽度	设计特征	材料	完成	包装数量
30849-402	73.8mm	3HP	紧凑型	不锈钢		1
30849-403	73.8mm	4HP	中尺寸	不锈钢		1

物料号	高度 (H)	机架宽度	设计特征	材料	完成	包装数量
30849-404	73.8mm	6HP	全尺寸	不锈钢		1
30849-406	148.8mm	4HP	中尺寸	不锈钢		1
30849-407	148.8mm	6HP	全尺寸	不锈钢		1
30849-658	73.8mm	4HP	中尺寸	铝	钝化	1
30849-670	148.8mm	4HP		铝	钝化	1
30849-682	73.8mm	6HP	全尺寸	铝	钝化	1
30849-694	148.8mm	6HP	全尺寸	铝	钝化	1

Table 2/2					
物料号	正面表面处理	反面表面处理	深度 (D)	宽度 (W)	快速发货
30849-402	未加工	未加工	1mm	13.9mm	No
30849-403	未加工	未加工	1mm	19mm	No
30849-404	未加工	未加工	1mm	29mm	No
30849-406	未加工	未加工	1mm	19mm	No
30849-407	未加工	未加工	1mm	29mm	No
30849-658	未加工	未加工	2.5mm	19mm	No
30849-670	未加工	未加工	2.5mm	19mm	No
30849-682	未加工	未加工	2.5mm	29mm	No

物料号	正面表面处理	反面表面处理	深度 (D)	宽度 (W)	快速发货
30849-694	未加工	未加工	2.5mm	29mm	No

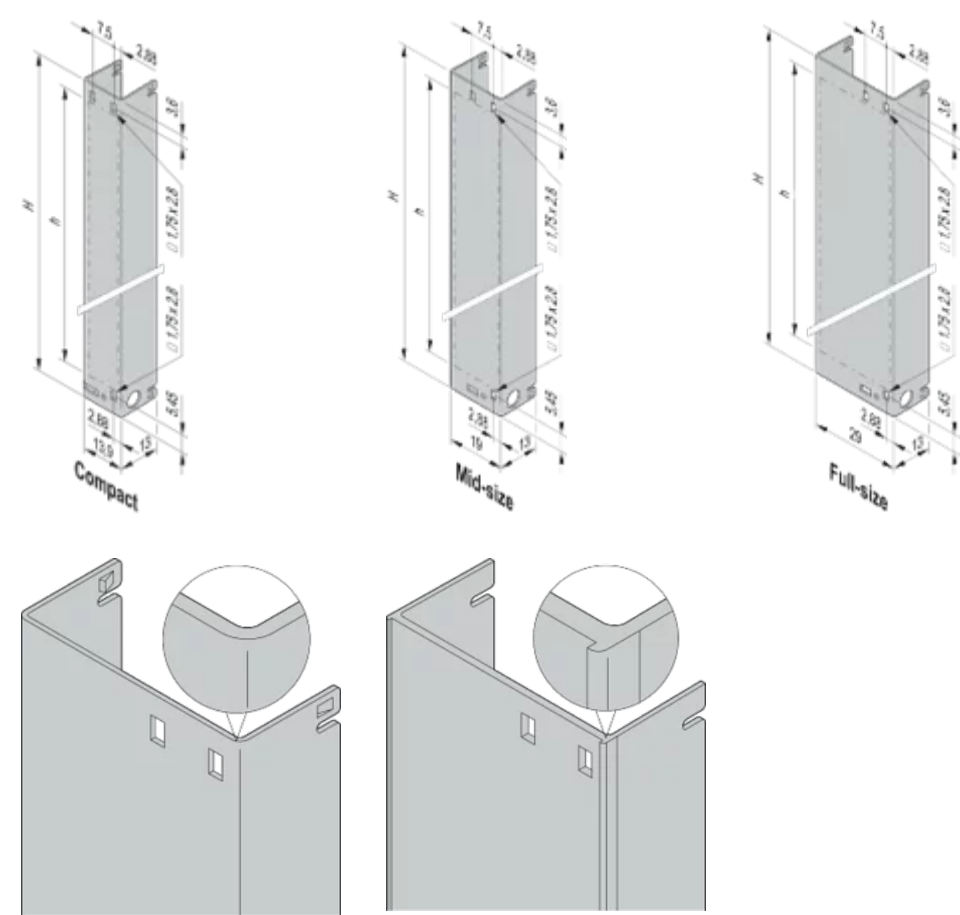

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE