


AMC 拉杆把手机制, AMC.0 R2.0

把手结构 AMC.0 修订版 2.0、MTCA.1 和 MTCA.4 模块。

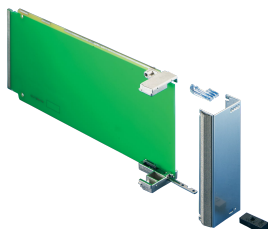

认证



功能

完整的拉手机构, 设计用于使能（热插拔）微动开关, 包括发光管

适用于所有 nVent SCHROFF AdvancedMC 模块

技术参数

类型: 助拔器

产品类型: 手柄

Table 1/2

物料号	设计特征	材料	手柄类型	包装数量	可燃性等级	颜色
20849-151	紧凑型	聚碳酸酯	单模块紧凑型	1	UL® 94V-0	黑色
20849-152	中尺寸	聚碳酸酯	单模块中尺寸	1	UL® 94V-0	黑色

物料号	设计特征	材料	手柄类型	包装数量	可燃性等级	颜色
20849-155	中尺寸	聚碳酸酯	双模块中尺寸	1	UL® 94V-0	黑色
20849-153	全尺寸	聚碳酸酯	单模块全尺寸	1	UL® 94V-0	黑色
20849-156	全尺寸	聚碳酸酯	双模块全尺寸	1	UL® 94V-0	黑色

Table 2/2		
物料号	搭配	快速发货
20849-151	MicroTCA 系统	No
20849-152	MicroTCA 系统	No
20849-155	MicroTCA 系统	No
20849-153	MicroTCA 系统	No
20849-156	MicroTCA 系统	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE