

ATCA Front Panel Kit With Spring Loading



AdvancedTCA

前面板，适用于带压铸尾端件的铝型材或不锈钢材质弹簧支撑IEA把手（柱塞式或杆式）。

认证



功能

前面板（使用压铸端件加固）

ATCA IEA 把手，带弹簧承载装置

EMC 织物垫片和固定材料

技术参数

机架宽度: 6HP
 机架高度: 8U
 附件类型: 前面板
 产品类型: 前面板


Table 1/2

物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-170	铝	钝化	1	未加工	未加工	1mm

物料号	材料	完成	包装数量	正面表面处理	反面表面处理	深度 (D)
20818-169	铝	钝化	1	未加工	未加工	1mm
20818-161	不锈钢		1	未加工	未加工	1mm
20818-160	不锈钢		1	未加工	未加工	1mm

Table 2/2			
物料号	高度 (H)	宽度 (W)	快速发货
20818-170	323.15mm	28.95mm	No
20818-169	323.15mm	28.95mm	No
20818-161	323.15mm	28.95mm	No
20818-160	323.15mm	28.95mm	No

图

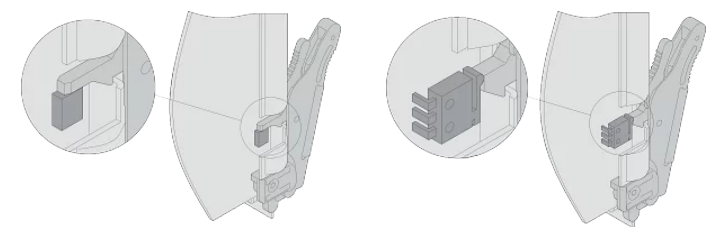

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE