


卡笼，可沿水平方向安装板卡

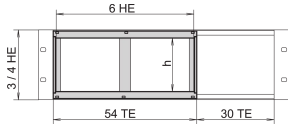

板笼为水平板卡提供了安装选项，便于6U板卡插在3U或4U高的插槽或者桌面仪器箱。请单独订购前面板，以组成装配套件。

认证



功能

适用在 3 或 4 U高插槽/机箱中水平安装双排欧卡电路板

技术参数

产品系列: EuropacPRO

产品类型: 安装套件

搭配: 插槽

Table 1/1

物料号	机架高度	机架宽度	包装数量	材料	类型	快速发货
24564-117	3U	20HP	1	铝, 锌合金	水平板安装	No
24564-118	3U	20HP	1	铝, 锌合金	水平板安装, 带有长唇	No
24564-217	4U	28HP	1	铝, 锌合金	水平板安装	No

其他产品详情

请单独订购前框架和 EMC 屏蔽材料。

需要 54 TE 空间。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE