


车载机架

适合持续振动、冲击、高温和高湿度环境。

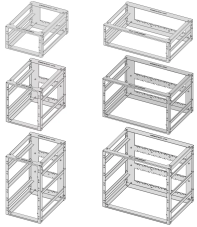

认证



功能

适用于移动铁路应用

可用于持续振动, 冲击, 高温, 和高湿度环境

适用于 1, 2, 或 3 U SNCF 插箱 (NF F61-005, CF 60-002)

后侧配有标准连接器; 横杆可以针对 SNCF 编码销进行自定义编码

横杆带有集成电缆槽

多个机架可以彼此叠加或并排放置

使用焊接工艺生产, 获得 EN 15085 (CL2) 认证

不锈钢焊缝钝化, 防止腐蚀

技术参数

静态负载: 25kg

深度: 341.8mm

产品类型: 机架

符合: SNCF NFF 61005; SNCF NFF 60002

框架材料: 钢

Table 1/2						
物料号	机架高度	高度	机架宽度	宽度	包装数量	材料
10170-017	9U	423.4mm	36HP	252.65mm	1	不锈钢
10170-016	9U	423.4mm	84HP	496.4mm	1	不锈钢
10170-015	3U	156.7mm	36HP	252.65mm	1	不锈钢
10170-012	6U	290mm	84HP	496.4mm	1	不锈钢
10170-014	3U	156.7mm	84HP	496.4mm	1	不锈钢
10170-013	6U	290mm	36HP	252.65mm	1	不锈钢

Table 2/2	
物料号	快速发货
10170-017	No
10170-016	No
10170-015	No
10170-012	No
10170-014	No
10170-013	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE