


组合式机箱安装套件

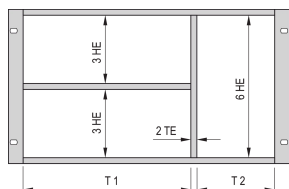

组合安装可将 6 U 高插箱或机箱拆分为 2 x 3 U 和 6 U 两部分。可提供不同版本。

认证



功能

旨在安装欧卡电路板（100 mm 高）和双高度欧卡电路板（233.35 mm 高）

6 U 装配区可拆分成：2 x 3 U, 1 x 6 U

技术参数

机架高度： 6U
 类型： 组合式
 产品系列： EuropacPRO
 产品类型： 安装套件
 搭配： 插箱

Table 1/1

物料号	包装数量	机架宽度 1	机架宽度 2	材料	快速发货
24562-420	1	20HP	62HP	铝, 锌合金	No
24562-440	1	40HP	42HP	铝, 锌合金	No

物料号	包装数量	机架宽度 1	机架宽度 2	材料	快速发货
24562-442	1	42HP	40HP	铝, 锌合金	No
24562-484	1	84HP		铝, 锌合金	No
24562-463	1	63HP	19HP	铝, 锌合金	No

其他产品详情

Please order separately: 前面板 6 U, 2 HP to cover the strut.

The following guide rails cannot be used: type "accessory", type "accessory, strengthened" and type "for 4.4" PCB".

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE