


Comptec 19" 桌面式机箱, 非屏蔽型

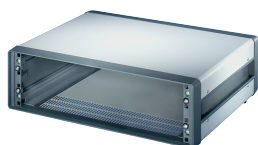

nVent SCHROFF Comptec 机箱可兼容 19" 机柜，用于安放 19" 插箱、19" 风扇托盘或 19" 前面板等组件。此机箱通常还用于桌面式应用。

认证



功能

桌面式机箱（已装配）

非屏蔽型

底板上的通风孔

压铸铝前后框架

含顶盖, 钢制底板和后面板

符合 DIN EN 62368-1

技术参数

产品类型: 仪器箱

类型: 适用于安装 19" 插箱和 19" 机箱的仪器箱

产品系列: Comptec

Table 1/3

物料号	机架高度	高度	机架宽度	深度	材料	包装数量
-----	------	----	------	----	----	------

10225-601	3U	153mm	84HP	300mm	铝, 钢	1
10225-602	4U	198mm	84HP	300mm	铝, 钢	1
10225-604	6U	286mm	84HP	300mm	铝, 钢	1
10225-612	3U	153mm	84HP	400mm	铝, 钢	1
10225-613	4U	198mm	84HP	400mm	铝, 钢	1
10225-615	6U	286mm	84HP	400mm	铝, 钢	1
10225-616	7U	331mm	84HP	400mm	铝, 钢	1
10225-618	9U	420mm	84HP	400mm	铝, 钢	1
10225-623	3U	153mm	84HP	500mm	铝, 钢	1
10225-624	4U	198mm	84HP	500mm	铝, 钢	1
10225-626	6U	286mm	84HP	500mm	铝, 钢	1
10225-627	7U	331mm	84HP	500mm	铝, 钢	1
10225-629	9U	420mm	84HP	500mm	铝, 钢	1
10225-637	6U	286mm	84HP	600mm	铝, 钢	1
10225-638	7U	331mm	84HP	600mm	铝, 钢	1
10225-640	9U	420mm	84HP	600mm	铝, 钢	1
10225-667	9U	420mm	84HP	400mm	铝	1

10225-670	12U	553mm	84HP	400mm	铝	1
10225-682	9U	420mm	84HP	500mm	铝	1
10225-685	12U	553mm	84HP	500mm	铝	1
10225-693	9U	420mm	84HP	600mm	铝	1
10225-696	12U	553mm	84HP	600mm	铝	1

Table 2/3						
物料号	可用高度	可用宽度	前部框架结构	制冷选项	符合	EMC 屏蔽
10225-601	134.2mm	451mm	单段	否	IEC 60297-3-100	否
10225-602	178.7mm	451mm	单段	否	IEC 60297-3-100	否
10225-604	267.6mm	451mm	单段	否	IEC 60297-3-100	否
10225-612	134.2mm	451mm	单段	否	IEC 60297-3-100	否
10225-613	178.7mm	451mm	单段	否	IEC 60297-3-100	否
10225-615	267.6mm	451mm	单段	否	IEC 60297-3-100	否
10225-616	312mm	451mm	单段	否	IEC 60297-3-100	否
10225-618	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-623	134.2mm	451mm	单段	否	IEC 60297-3-100	否
10225-624	178.7mm	451mm	单段	否	IEC 60297-3-100	否
10225-626	267.6mm	451mm	单段	否	IEC 60297-3-100	否

物料号	可用高度	可用宽度	前部框架结构	制冷选项	符合	EMC 屏蔽
10225-627	312mm	451mm	单段	否	IEC 60297-3-100	否
10225-629	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-637	267.6mm	451mm	单段	否	IEC 60297-3-100	否
10225-638	312mm	451mm	单段	否	IEC 60297-3-100	否
10225-640	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-667	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-670	534mm	451mm	单段	否	IEC 60297-3-100	否
10225-682	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-685	534mm	451mm	单段	否	IEC 60297-3-100	否
10225-693	400.9mm	451mm	单段	否	IEC 60297-3-100	否
10225-696	534mm	451mm	单段	否	IEC 60297-3-100	否

Table 3/3					
物料号	完成	防护等级	静态负载	宽度	快速发货
10225-601	粉末涂层	IP20	40kg	520mm	No
10225-602	粉末涂层	IP20	40kg	520mm	No
10225-604	粉末涂层	IP20	40kg	520mm	No
10225-612	粉末涂层	IP20	40kg	520mm	No

物料号	完成	防护等级	静态负载	宽度	快速发货
10225-613	粉末涂层	IP20	40kg	520mm	No
10225-615	粉末涂层	IP20	40kg	520mm	No
10225-616	粉末涂层	IP20	40kg	520mm	No
10225-618	粉末涂层	IP20	40kg	520mm	No
10225-623	粉末涂层	IP20	40kg	520mm	No
10225-624	粉末涂层	IP20	40kg	520mm	No
10225-626	粉末涂层	IP20	40kg	520mm	No
10225-627	粉末涂层	IP20	40kg	520mm	No
10225-629	粉末涂层	IP20	40kg	520mm	No
10225-637	粉末涂层	IP20	40kg	520mm	No
10225-638	粉末涂层	IP20	40kg	520mm	No
10225-640	粉末涂层	IP20	40kg	520mm	No
10225-667	粉末涂层	IP20	40kg	520mm	No
10225-670	粉末涂层	IP20	40kg	520mm	No
10225-682	粉末涂层	IP20	40kg	520mm	No
10225-685	粉末涂层	IP20	40kg	520mm	No
10225-693	粉末涂层	IP20	40kg	520mm	No

物料号	完成	防护等级	静态负载	宽度	快速发货
10225-696	粉末涂层	IP20	40kg	520mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE