


沉头螺钉, Torx

盘头螺钉。

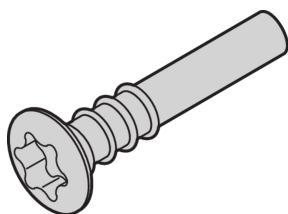

认证



功能

用螺钉将顶盖/底盖安装到CassettePRO箱体上

技术参数

类型: 沉头螺钉

产品类型: 螺钉

Table 1/2

物料号	长度	材料	完成	包装数量	螺纹尺寸	产品系列
24812-751	6mm	不锈钢		100	M2.5	
21191-589	8mm	钢	镀镍	100	M3	

物料号	长度	材料	完成	包装数量	螺纹尺寸	产品系列
24812-501	20mm	钢	镀镍	100	M3	EuropacPRO, RatiopacPRO, RatiopacPRO AIR, CompacPRO, PropacPRO, MultipacPRO

Table 2/2			
物料号	搭配	认证	快速发货
24812-751	插箱, 仪器箱, 机箱		No
21191-589	前面板		No
24812-501	插箱, 仪器箱, 机箱	RoHS	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE