


沉头螺钉

埋头螺钉可在插箱或桌面式机箱中用于多种安装方式。

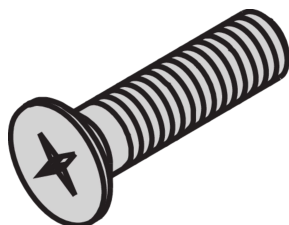

认证



功能

沉头螺钉

技术参数

产品类型： 螺钉

Table 1/2

物料号	长度	材料	完成	包装数量	螺纹尺寸	高度
24560-182	12mm	钢	镀锌	4	M5	
24560-158	7.7mm	钢	镀锌	100	M2.5	
21100-429	8mm	钢	镀镍	100	M2.5	
21100-507	12mm	钢	镀镍	100	M2.5	

物料号	长度	材料	完成	包装数量	螺纹尺寸	高度
21100-500	10mm	钢	镀镍	100	M2.5	
21100-649	10mm	钢	镀锌	100	M2.5	
21100-542	8mm	钢	镀镍	100	M3	
24560-139	5mm	钢	镀锌	100	M4	
24560-145	14mm	钢	镀锌	100	M4	
24560-183	12mm	钢	镀锌	100	M5	
24560-164	8mm	钢	镀镍	100	M2.5	4.7mm

Table 2/2						
物料号	类型	宽度	搭配	螺纹类型	扭矩	快速发货
24560-182	沉头螺钉		前面板		2.4N • m	No
24560-158	沉头螺钉		前面板			No
21100-429	螺钉		前面板			No
21100-507	螺钉		前面板			No
21100-500	螺钉		前面板			No
21100-649	螺钉		前面板			No
21100-542	螺钉		前面板			No
24560-139	沉头螺钉		前面板		1.3N • m	No

物料号	类型	宽度	搭配	螺纹类型	扭矩	快速发货
24560-145	沉头螺钉		前面板		2.4N • m	No
24560-183	沉头螺钉		前面板		2.4N • m	No
24560-164	沉头螺钉	4.7mm	前面板	公制		No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE