


CPCI 背板

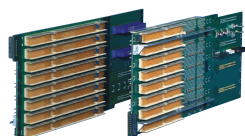

nVent SCHROFF CompactPCI 背板凭借 SMD 组件、陶瓷电容器和压合式连接器实现了一流的信号完整性和 MTBF 值。

认证



功能

数字 GND 可通过螺钉连接/隔离机箱 GND

V(I/O) 可设置为 +3.3 V 或 +5 V

外层作为 GND 表面

带连接状态信号 (SMCQ) 的应用插头

采用陶瓷电容器，具有出色的高频率噪声抑制能力和极高的 MTBF 值

PICMG 2.9 智能平台管理总线 (IPMB) 连接器

符合 PICMG 2.9 的智能平台管理总线 (IPMB) 连接器

技术参数

Table 1/3

物料号	产品类型	插槽数	机架高度	背板类型	系统插槽	槽宽
23006-792	背板	2	7U	CompactPCI, 64 位	左	4HP

物料号	产品类型	插槽数	机架高度	背板类型	系统插槽	槽宽
23006-793	背板	2	7U	CompactPCI, 64 位	左	4HP
23006-794	背板	2	9U	CompactPCI, 64 位	左	4HP
23006-799	背板	4	7U	CompactPCI, 64 位	左	4HP
23006-798	背板	6	7U	CompactPCI, 64 位	左	4HP
23006-601	背板	8	6U	CompactPCI, 64 位, H.110 总线	右	4HP
23006-611	背板	8	9U	CompactPCI, 64 位, PSB, H.11 0 总线	左	4HP
23006-795	背板	4	7U	CompactPCI, 64 位	左	4HP
23006-796	背板	6	9U	CompactPCI, 64 位	左	4HP
23006-797	背板	8	9U	CompactPCI, 64 位	左	4HP

Table 2/3						
物料号	电压 I/O	连接器类型	电源连接器类型	多功能连接器类型	宽度	包装数量
23006-792	5V	HM 2.0	ATX (公头) 连接器		39.64mm	1
23006-793	5V	HM 2.0	Mini-fit 10-针	SMCQ, 12 针	39.64mm	1
23006-794	5V	HM 2.0	(1) P47	SMCQ, 12 针	39.64mm	1
23006-799	5V	HM 2.0	Mini - fit 24 针	SMCQ, 12 针		1
23006-798	5V	HM 2.0	Mini - fit 24 针	SMCQ, 12 针	121mm	1

物料号	电压 I/O	连接器类型	电源连接器类型	多功能连接器类型	宽度	包装数量
23006-601	5V	HM 2.0	用于 M4 电缆连接片的电 源插头	SMCQ, 12 针	161.56mm	1
23006-611	5V	HM 2.0	(2) P47	SMCQ, 12 针	161.56mm	1
23006-795	5V	HM 2.0	(2) P47	SMCQ, 12 针		1
23006-796	5V	HM 2.0	(2) P47	SMCQ, 12 针	121mm	1
23006-797	5V	HM 2.0	(2) P47	SMCQ, 12 针	161.56mm	1

Table 3/3

物料号	快速发货
23006-792	No
23006-793	No
23006-794	No
23006-799	No
23006-798	No
23006-601	No
23006-611	No
23006-795	No
23006-796	No
23006-797	No

可应要求提供其他配置。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE