


双测试插座，Ø 2 mm

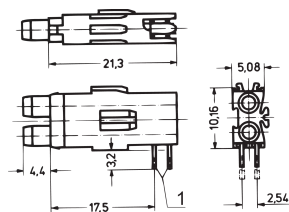

适用于安装面 1 和 2 的双测试插孔，短型和长型。

焊接时长最多施加 5 秒。波峰焊时应保护塑料体免受焊波的影响。

认证



功能

用于前面板的双测试插孔

用于安装面1的短型

技术参数

直径: 2mm

产品类型: 插座

Table 1/2

物料号	类型	包装数量	交流电压	最大电流	在 50 Hz 时的测试电压	环境温度
69004-089	长型，适用安装面 1	1	30V	1A	1kV	-25 to 70°C
69004-131	短型，适用安装面板 1	1	30V	1A	1kV	-25 to 70°C
69004-090	长型，适用安装面 2	10	30V	1A	1kV	-25 to 70°C

Table 2/2			
物料号	焊接温度	可燃性等级	快速发货
69004-089	260°C	UL® 94V-0	No
69004-131	260°C	UL® 94V-0	No
69004-090	260°C	UL® 94V-0	No

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

Dimensions of connecting pins: 0.3 × 0.6 mm.

Required front panel drill hole: Ø 4 mm.

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE