


适用 19 英寸风扇托盘的 1 U 空气导流器，支持 6 台风扇，前面开孔，330 mm，RAL 9005

物料号

10713-143

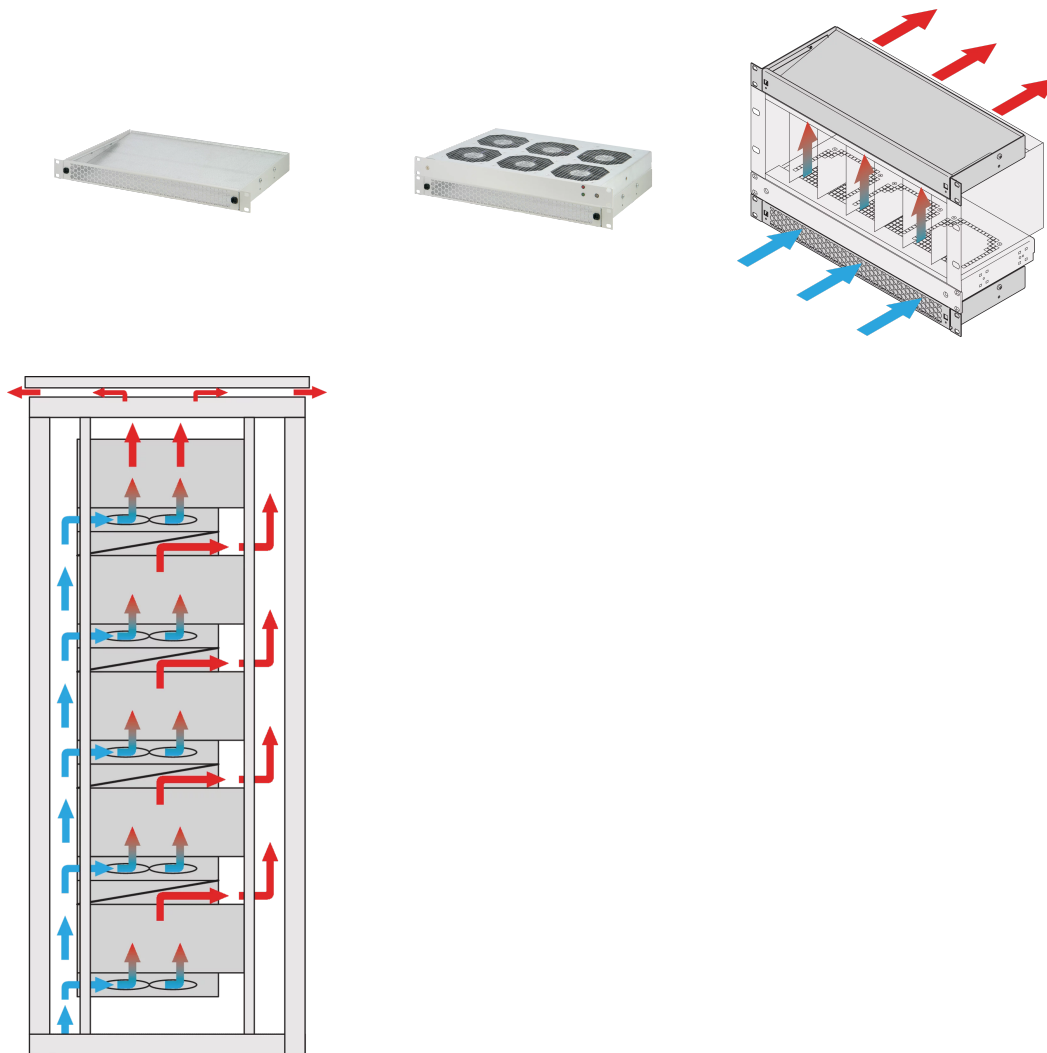

1 U 高的导风板，用于引导空气从正面流向顶部，或从底部流向背面。

认证



功能

装配选项： – 一个风扇盘：从前部向上抽吸冷空气 – 两个风扇盘：从前部抽吸冷空气, 向上抽吸并导流到后部（参阅应用图）

如安装 19" 风扇盘，冷却能力更佳

通过改变气流方向避免热量垂直积聚

可选过滤垫, 方便现场更换

产品属性

产品类型: 导风

产品系列: Novastar; Varistar

搭配: 19" 风扇盘

完成: 粉末涂层

Gross Weight: 1.759kg

材料: 钢

包装数量: 1

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE