
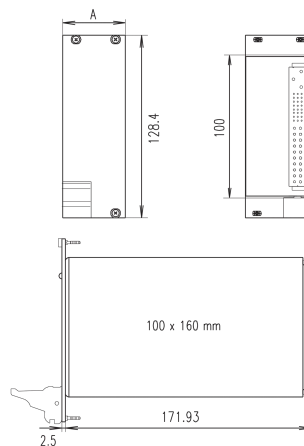


适于 CompactPCI 的 PSU 19", DC/DC, 3 U, 8 HP

物料号

13100-142

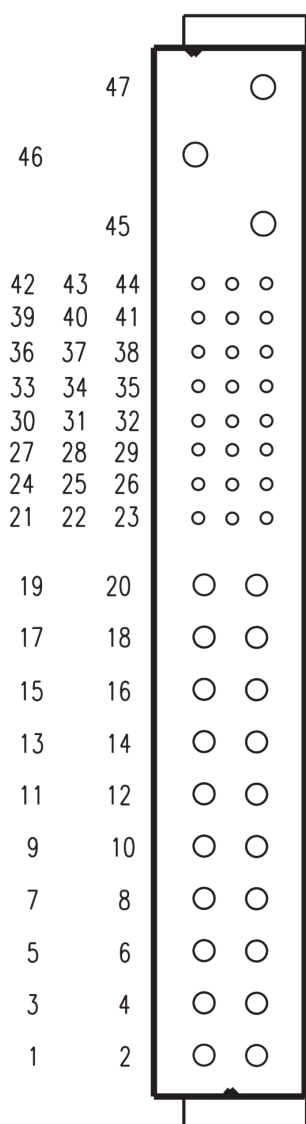

Pluggable 19" Power Supply with P47 connector, for CompactPCI applications.

认证



功能

- P47 连接器和 CompactPCI 信号
- 4 种输出电压
- 带有均流总线 (CSB) 的冗余运行, 热插拔

产品属性

- 产品类型: 电源
- 类型: 19" 直流/直流转换器
- 搭配: CompactPCI 和 VME64x
- 直流输入电压: 36 – 75V
- 电源: 250W
- 输出电压数: 4
- 电压 1: 5V
- 电流 1: 40A
- 电压 2: 3.3V
- 电流 2: 40A
- 电压 3: 12V
- 电流 3: 5.5A
- 电压 4: -12V
- 电流 4: 2A
- 机架高度: 3U
- 机架宽度: 8HP
- 深度: 171.93mm
- Net Weight: 0.94kg
- 包装数量: 1

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE