


# 符合 IEL 标准的模件盒微动开关，IET 把手，含电缆和插头

## 物料号

**20817-606**

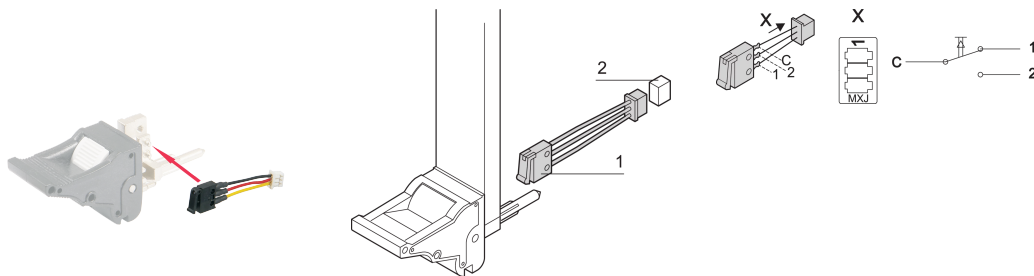

适用于 IEL 或 IET 把手的微型开关。微型开关也适合偏移版本的把手。

## 认证



## 功能

塑料, PC, UL 94 V-0

与之配合的连接器不包括在交付范围内

最大开关电流 50 mA

电气寿命  $\geq 20,000$  开关

机械寿命  $\geq 20,000$  开关

Molex 连接器

Molex 挤压触点和固定夹

产品属性

- 产品类型: 开关
- 搭配: 前面板
- 材料: 聚碳酸酯
- 包装数量: 10

其他产品详情

交付中未包含配合连接器。适合Molex 连接器，例如 53261-0319、53048-0310、53047-0310、53398-0319、51047-0300。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE