


# IET 型助插器/助拔器把手，IET 型，黑色手柄，灰色按钮，顶部；10 个

## 物料号

**20817-708**

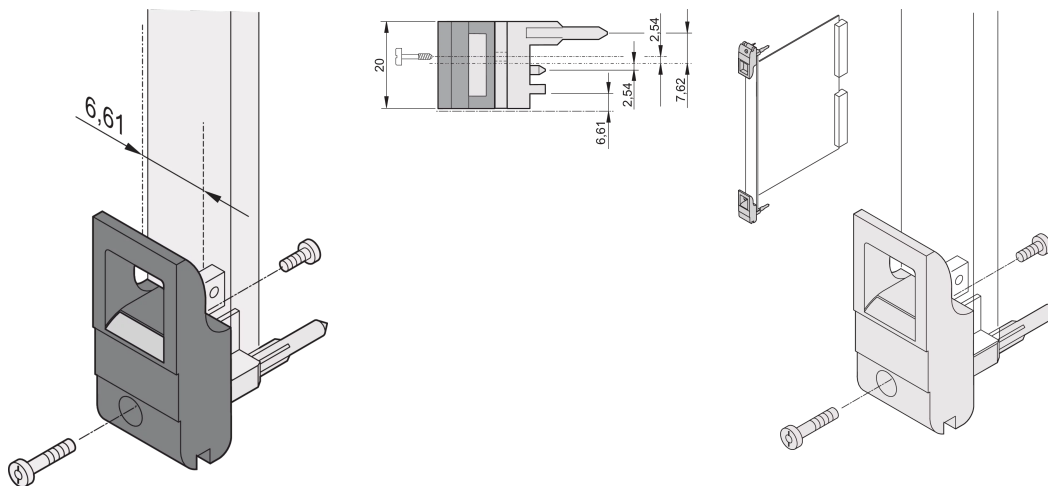

助插器/助拔器把手，IET 型，符合 IEEE 1101.10 标准。0,1" 偏移。其中两个把手可以提供 700 N 的单杠杆力（每对）。

## 认证



## 功能

插入和拔出力高达 700 N（每对）

符合 IEEE 1101.10 和 IEC 60297-3-102 标准

可安装微型开关

0.1" 偏移用于带 背板贴片的 电源模块


产品属性

|                      |
|----------------------|
| 包装数量: 10             |
| 手柄类型: IET; 顶部前部      |
| 可燃性等级: UL® 94V-0     |
| 颜色: 墨黑色              |
| 颜色代码: RAL 9005       |
| 符合: EN 45545-2       |
| 深度 (D): 39.15mm      |
| 高度 (H): 44.65mm      |
| 材料: 聚碳酸酯; 锌合金        |
| 产品类型: 手柄             |
| 类型: 助插器/助拔器, 0.1" 偏移 |
| 宽度 (W): 19.8mm       |
| 搭配: 前面板              |

其他产品详情

请单独订购编码键和微型开关。

图

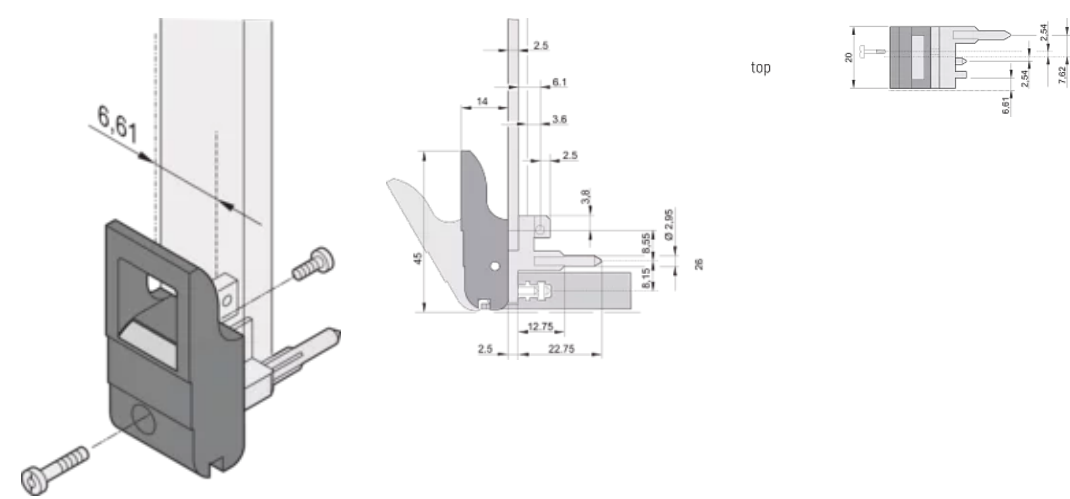

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 [www.nvent.com](http://www.nvent.com) 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

## North America

All locations

+1.763.422.2661

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)

## Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

[nvent.com/schroff](https://nvent.com/schroff)



我们强大的品牌组合:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**