
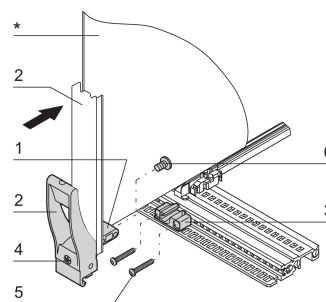
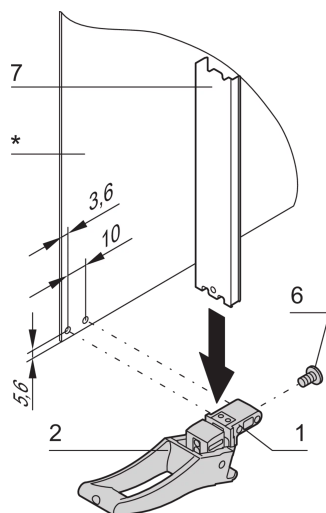


XL 型助插器/助拔器把手；10 个

物料号

20817-874

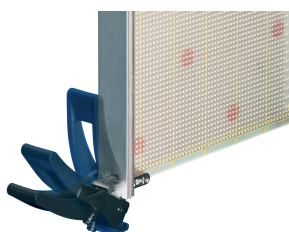

支持高达 1500 N

的插入和拔出力（每对）。通过双螺栓实现板卡固定，牢固耐用。插入功能借助导向部件实现，该部件装配在水平轨道上。

认证



功能

可承受高达 1500 N 的插入力和拔出力（每对）

PA 把手, 内含玻璃纤维, 增强结构强度, UL 94V 0

通过双螺栓实现板卡固定，牢固耐用

可安装微动开关

对称设计, 板卡顶部/底部的把手为相同型号

产品属性

产品类型: 手柄
类型: 助插器/助拔器
搭配: 前面板
手柄类型: XL
宽度: 20.1mm
材料: 锌合金; 聚酰胺
颜色: 墨黑色
可燃性等级: UL® 94V-0
包装数量: 10
颜色代码: RAL 9005
深度: 42.39mm
高度: 73.57mm

其他产品详情

请单独订购前面板和微型开关。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE