


带 IEL 把手的 FMC 插入式单元套件，黑色，U 形前面板屏蔽（泡棉），3 U，4 HP

物料号

20836-253

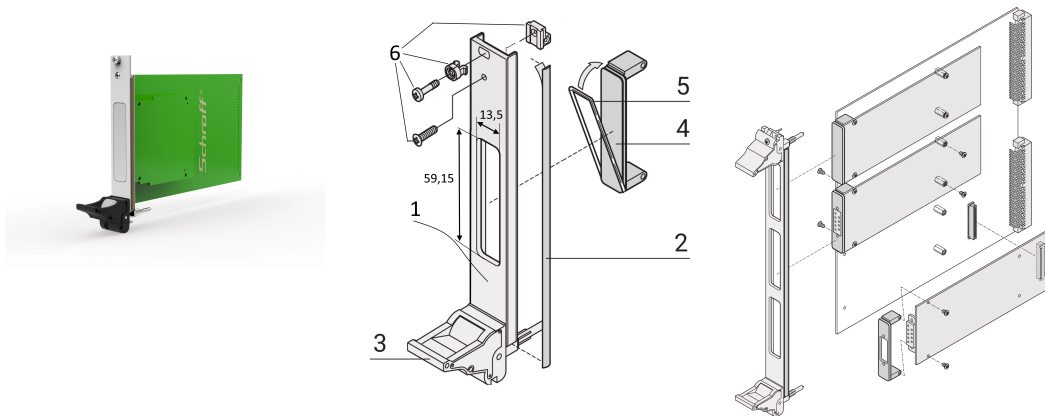

FMC 面板符合 Vita 57.1 规范。覆盖整个前面板上的开孔。

认证



功能

符合 Vita 57.1 技术参数

适用于单个 69.0 x 76.5 mm 模块或两个 139.0 x 76.5 mm 模块

带有 IEL 把手的铝型材面板

产品属性

机架高度: 3U

包装数量: 1

手柄类型: IEL
安装: 正面螺钉安装
垫片类型: 织物 EMC
正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
符合: FMC 夹层板, Vita 57.1
EMC 屏蔽: 是
完成: 阳极氧化; 钝化
高度: 128.4mm
材料: 铝
产品类型: 前面板
机架宽度: 4HP
类型: 带把手的前面板 (PIU)
宽度: 20mm
Net Weight: 0.1kg

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE