


面板套件，帶 IEL 把手，屏蔽，黑色 3 U，6 HP

物料号

20848-587

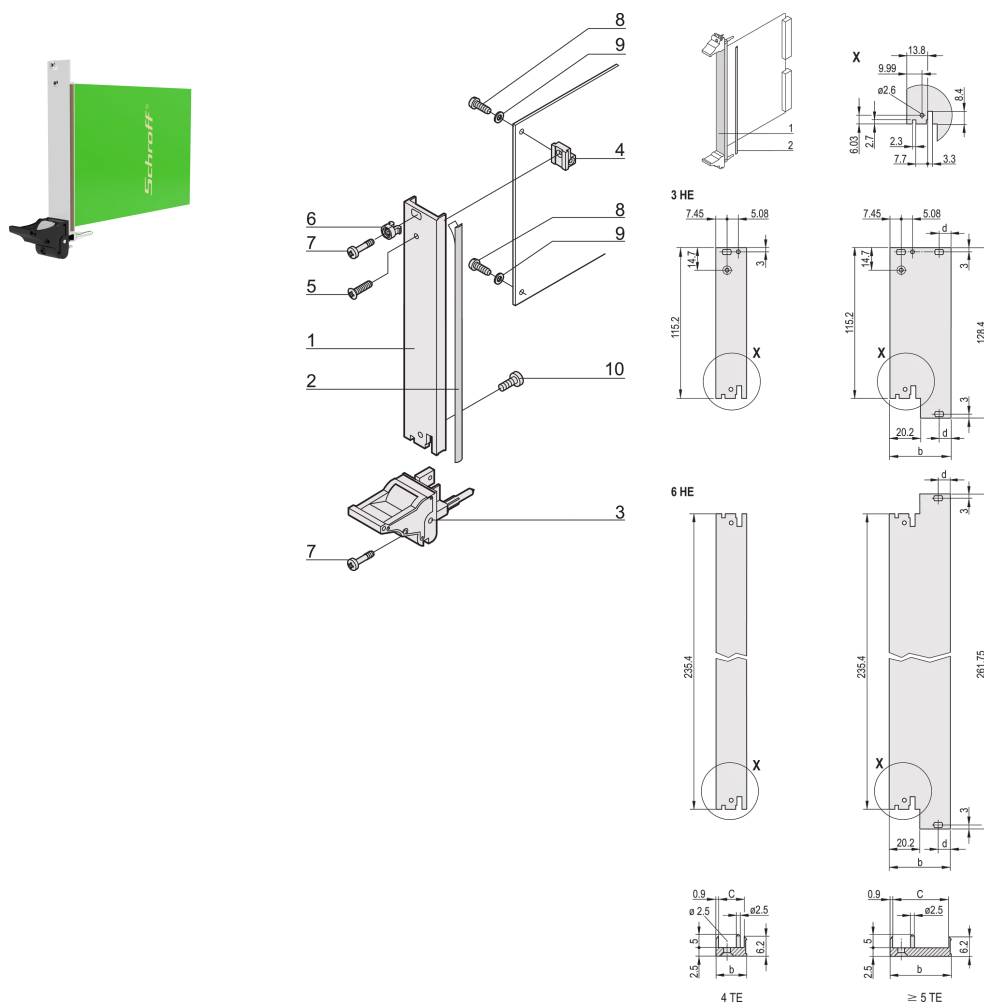

面板套件，带 IEL 助拔器黑色把手，3 U，前组件。U 型前面板带 EMC 导电布屏蔽条

认证




功能

- 带EMC导电布屏蔽条的 U 型前面板
- 可承受高达 700 N 的插入力和拔出力（每对）
- 可安装微型开关
- 可根据 IEC 60297-3-103/IEEE 1101.10 标准安装编码键

产品属性

- 机架宽度: 6HP
- 包装数量: 1
- 手柄类型: IEL
- 安装: 正面螺钉安装
- 垫片类型: 织物 EMC
- 正面表面处理: 阳极氧化
- 反面表面处理: 碱蚀
- 边缘处理: 否
- 符合: IEC 60297-3-102; IEEE 1101.10; IEC 60297-3-103; IEEE 1101.1/11
- EMC 屏蔽: 是
- 完成: 阳极氧化; 钝化
- 高度 (H): 128.4mm
- 材料: 铝
- 产品类型: 前面板
- 机架高度: 3U
- 类型: 带把手的前面板 (PIU)
- 宽度 (W): 30.1mm

图

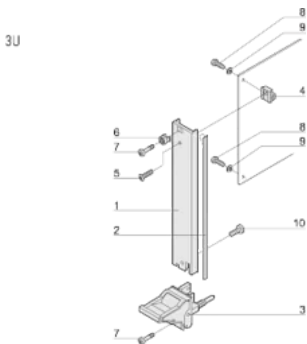

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE