


Front Panel EMC Textile Shielding Kit, -40...+85°C, 6 U, 100个

物料号

21102-856

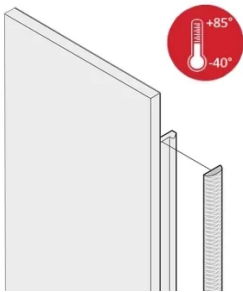

导电布 EMC 屏蔽条，可插入 U

型前面板右侧的插槽。垫片将粘在前面板上。适合高达 +85°C 的宽温环境。

认证



功能

EMC导电布屏蔽条横向固定在前面板上部或型材右侧的凹槽中，具体视情况而定。

型材密封件，可以粘合到 19" 法兰或后角的接触表面上，实现U 型前面板的导电连接

温度范围 - 40 °C ... +85 °C

产品属性

机架高度: 6U

包装数量: 100

材料: 热塑性合成橡胶

产品系列: EuropacPRO; PropacPRO; RatiopacPRO AIR; PropacPRO; 框架式插入单元


产品类型: 屏蔽套件

搭配: 插箱; 仪器箱; 前面板

其他产品详情

需要 EMC 导电布垫片来为前面板提供屏蔽防护。

图

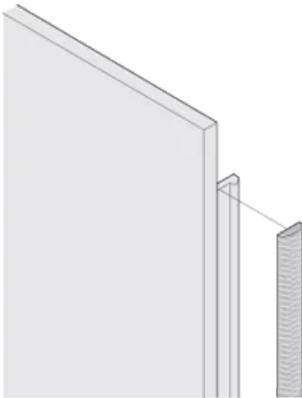

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE