


适于 Varistar ， Novastar， Eurorack 的 19" 伸缩层板， 70 kg， RAL 7021， 800W 700D

物料号

21130-374

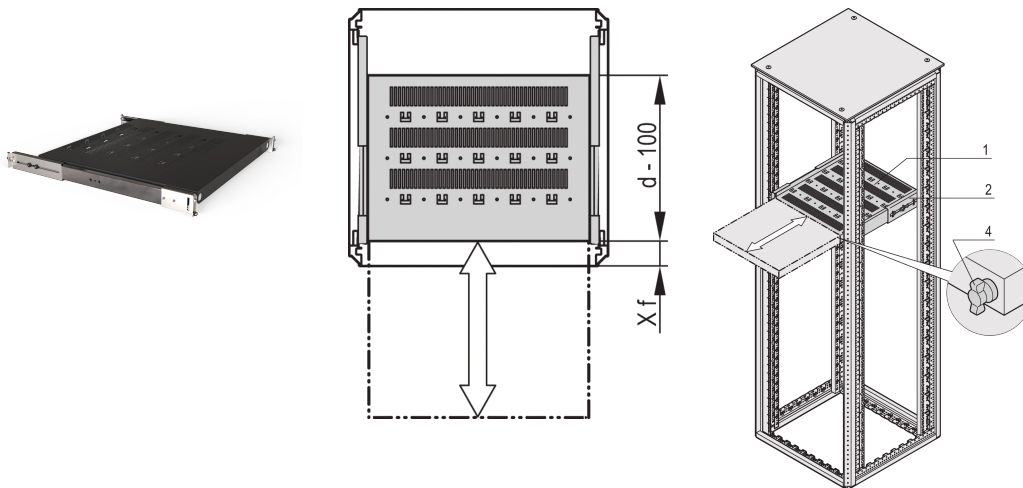

Varistar、Novastar 和 Eurorack 19" 层板，静态承载能力为 70 kg，有孔，便于装配。

认证



功能

通风孔用于装配电缆扎带

静态承载能力 70 千克

包含伸缩滑轨

可用 T 形锁锁闭

不锈钢, 1.5 mm

便于固定电缆扎带的T型孔

锤头型穿孔, 用于使用电缆扎带装配

产品属性

类型: 伸缩机架

宽度: 600mm

深度: 565mm

包装数量: 1

颜色: 暗灰色

颜色代码: RAL 7021

完成: 粉末涂层

材料: 钢

产品系列: Varistar; Eurorack; Novastar

产品类型: 货架

搭配: Varistar CP

Gross Weight: 5kg

其他产品详情

用于在框架上安装伸缩滑轨的安装支架, 请单独订购。

请单独订购 T 形锁。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告, 可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE