


适用于 Varistar、Novastar、Eurorack 的伸缩式通用机架，70 kg，RAL 7035，800W 600D

物料号

22130-373

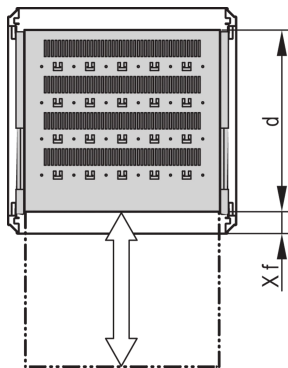

Varistar、Novastar 和 Eurorack 19" 层板，静态承载能力为 70 kg，有孔，便于装配。

认证



功能

通风孔用于装配电缆扎带

静态承载能力 70 千克

包含伸缩滑轨

可用 T 形锁锁闭

不锈钢，1.5 mm

便于固定电缆扎带的 T 型孔

锤头型穿孔，用于使用电缆扎带装配

产品属性

类型: 伸缩机架
宽度: 600mm
深度: 477mm
包装数量: 1
颜色: 浅灰色
颜色代码: RAL 7035
完成: 粉末涂层
材料: 钢
产品系列: Varistar; Eurorack; Novastar
产品类型: 货架
Gross Weight: 8.68kg

其他产品详情

用于在框架上安装伸缩滑轨的安装支架，请单独订购。

请单独订购 T 形锁。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或咨询您的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE