


RatiopacPRO 19"

塔式机箱，可改装的屏蔽，前边框，4 U，84 HP，495 mm

物料号

24571-395

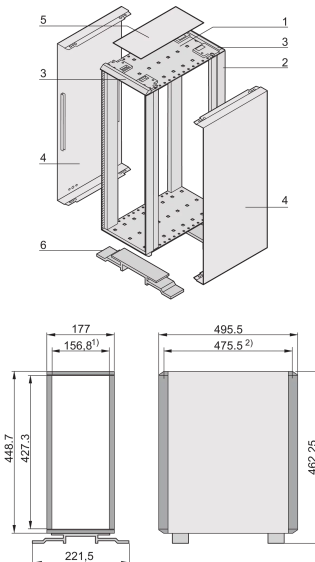

nVent SCHROFF RatiopacPRO 塔式机箱可为 19" 组件提供电子保护。这种灵活、可靠的仪器箱可轻松从桌面式转换为 19" 机架安装仪器箱，包含四种不同的选项。此版本的机箱可为桌面式应用实现美观的外观设计和提供支脚。

认证



功能

基于 RatiopacPRO 的机箱，带机箱支脚

安装空间 4 U, 84 HP, 深度 475 mm

可加装 EMC 屏蔽组件

对称设计, 前后侧结构相同

符合 DIN EN 62368-1

产品属性

产品类型: 仪器箱

产品系列: RatiopacPRO

类型: 塔式

机架高度: 4U

高度: 177mm

可用高度: 156.8mm

机架宽度: 84HP

宽度: 448.9mm

可用宽度: 432mm

深度: 495.5mm

EMC 屏蔽: 无 (可改装)

静态负载: 25kg

防护等级: IP20

前部框架结构: 侧面饰件; 水平横梁

制冷选项: 否

符合: IEC 60297-3-101; IEC 60297-3-102; IEEE 1101.1; IEEE 1101.10; IEEE 1101.11

包装数量: 1

完成: 钝化; 粉末涂层

材料: 铝

Net Weight: 4kg

其他产品详情

可定制 (特殊颜色或尺寸)。

定制解决方案 (支持顶盖、底板或侧面板开孔)。

提供装配服务, 一件起售。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE