


# CPCI 系统，带 ATX PSU，3 U，8 槽

## 物料号

**24579-031**

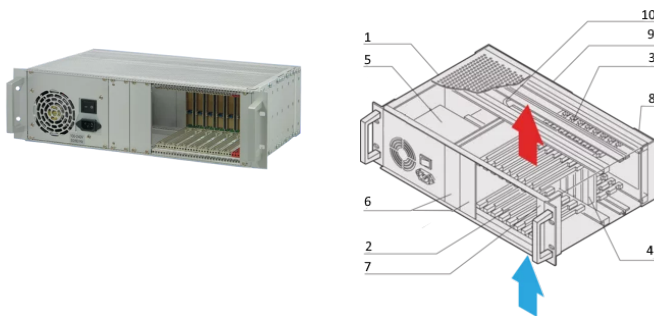

无风扇 3 U CompactPCI 系统，带垂直卡笼，适用于八个 3U 板和八个 RTM 板。带内置 ATX 电源。

## 认证



## 功能

符合 IEC 60297 - 3 - 101、- 102、- 103 标准以及 IEEE 1101.1, 1101.10/11，背板符合 PICMG 2.0 修订版 3.0 标准

系统含垂直卡槽。前插板卡：3 U, 160 mm深; 后部 I/O：3 U, 80 mm深

8 槽位背板, 3 U, 32 位; 右侧系统插槽; 可使用 8 HP 宽的 CPU

对流散热, 风道从下往上

可选安装slimline DVD驱动和硬盘

ATX PSU, 300 W

## 产品属性

产品类型: 系统

插槽数: 8

|                      |
|----------------------|
| 类型: 19" 机架安装         |
| 背板类型: 3 U CompactPCI |
| 数据传输: 32 位 PCI 总线    |
| 每插槽的功率: 10W          |
| 交流输入电压: 100 – 240V   |
| 机架高度: 3U             |
| 电源类型: 1块 ATX PSU     |
| 包含电源: 是              |
| 后部 I/O: 是            |
| 符合: PICMG 2.0 R3.0   |
| 深度: 275mm            |
| 高度: 132.55mm         |
| Net Weight: 8.86kg   |
| 包装数量: 1              |

其他产品详情

可应要求提供定制系统。

警告

North America

All locations  
+1.763.422.2661  
Chat with us:  
nvent.com/schroff

Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
nvent.com/schroff

Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
nvent.com/schroff

Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
nvent.com/schroff



我们强大的品牌组合:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE