


框架式模件盒导轨，5 对

物料号

24812-101

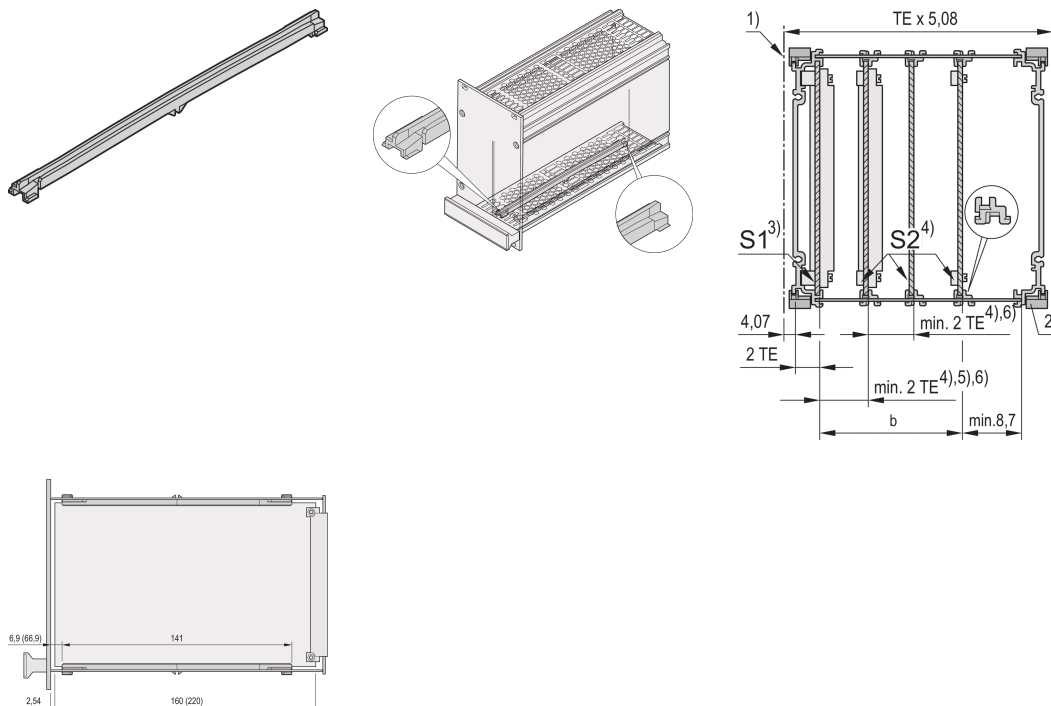

导轨可以安装在开孔的顶盖/底盖上。如果要从插槽 2 装配 PCB，则需要此装置。

认证



功能

支持插槽 2 所需的 PCB 固定

凹槽宽度 2 mm

红色

PBT, UL, 94, V-0


产品属性

产品类型: 导轨
类型: 框架式插入单元
搭配: 框架式插入单元
板深度: 160mm
槽宽: 2
材料: 聚碳酸酯
颜色: 红色
包装数量: 10
包装单位: 对

其他产品详情

导轨适合 167 mm和 227 深的模块盒。

图

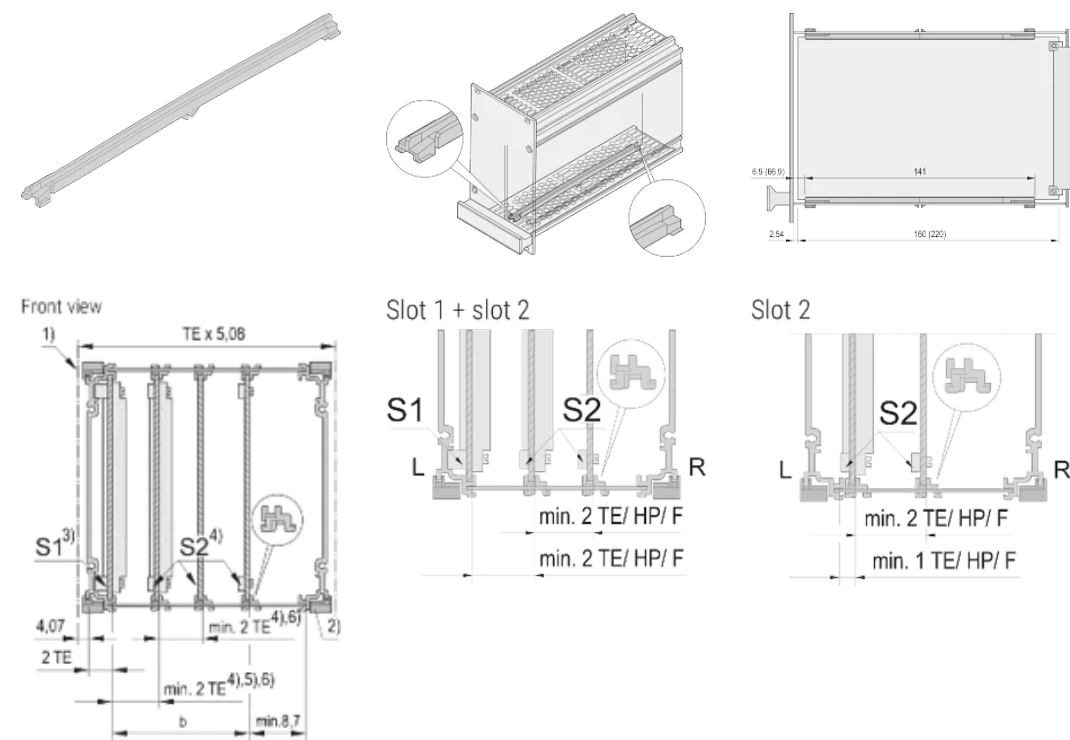

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE