




框型模件盒 PRO 套件，屏蔽型，穿孔，1 个连接器，3 U，42 HP，167 mm

物料号



24813-242

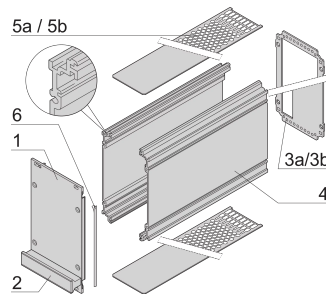

3 U Front panel shieldable

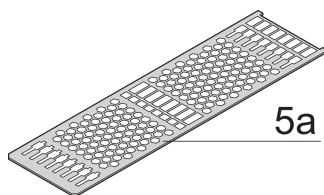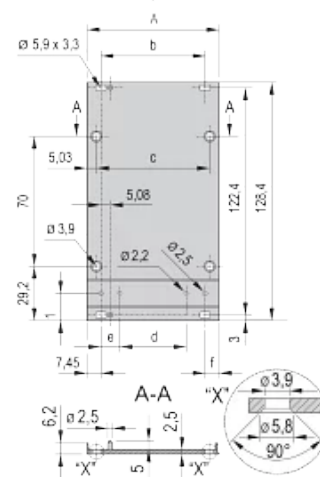

5a

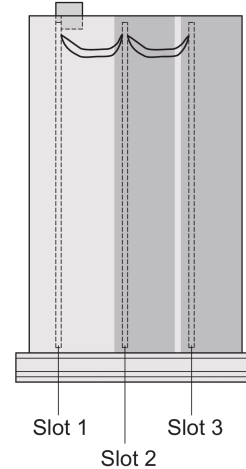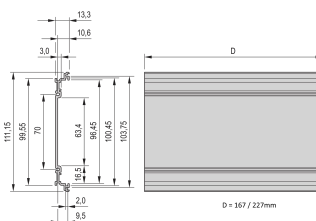

防止 PCB 遭受机械损坏和静电放电积聚；适用于欧洲板规格；与带一个开孔（用于一个连接器）的面板搭配。



功能

带网孔的盖板, 弹簧承载装置 (气流约 60%)

后面板, 带有用于单个连接器的开孔 (符合 EN 60603, DIN 41612, 结构类型: B, C, D, F, H, Q, R, S)

挤出侧板, 右侧和左侧有凹槽, 可插入 PCB (板卡的位置距离左侧板距离符合标准)

产品属性

机架高度: 3U

机架宽度: 42HP

深度 (D): 167mm

手柄类型: 梯形

包装数量: 1

EMC 垫片类型: 织物

后面板类型: 单连接器开孔

盖板类型: 穿孔盖板, 用于导轨

正面表面处理: 阳极氧化

反面表面处理: 导电

冷却: 穿孔

EMC 屏蔽: 是

完成: 阳极氧化; 钝化

材料: 铝

产品类型: 模件盒


类型: 框架式插入单元 PRO

其他产品详情

请单独订购导轨。

To fit further boards without rear connector, guide rail (part no. 24812 - 301) and 'Board fixing from slot 2' (part no. 24812 - 301 + screw part no. 24560 - 178) are required, 2 guide rails, 2 rear panel holders and board fixing for slot 1 and

one slot 2 are already included.

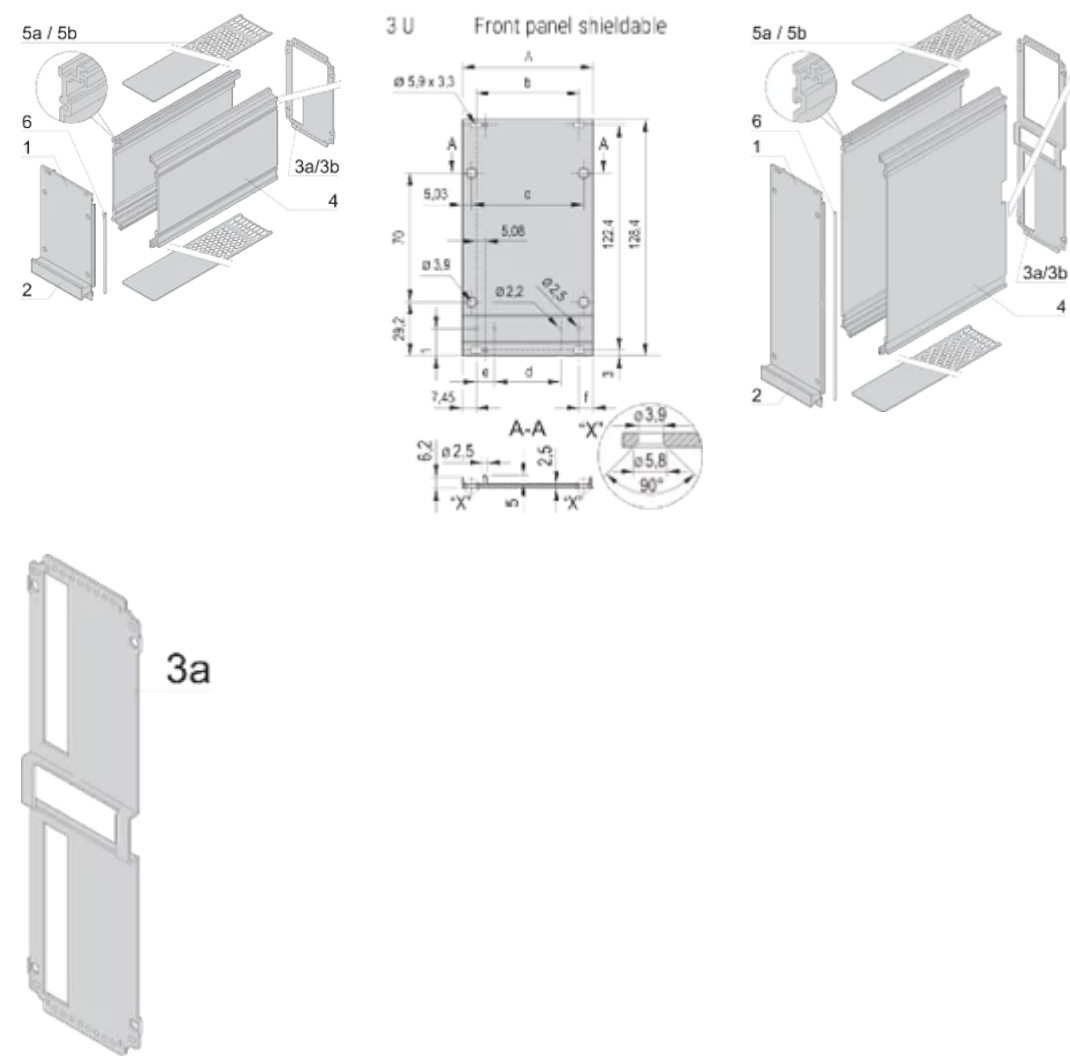

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE