


19" Front Panel With D-Sub Cutout, 3x9-pin, 3U, 4 HP, 2.5 mm, 铝, RAL 7035

物料号

30118-332

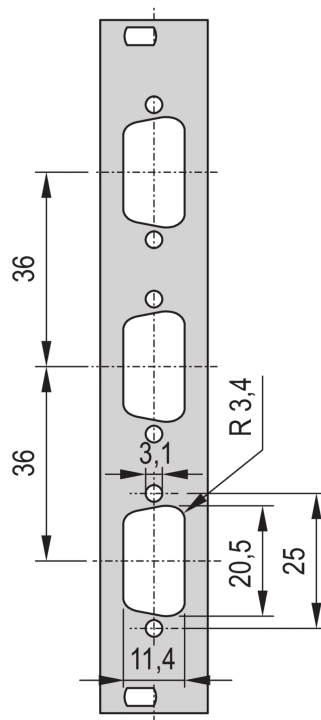

19" 前面板，带 SUB-D 开孔或 FDDI 开孔。

认证



功能

19 英寸前面板，带 Sub-D 开孔, ST 类型 3 或 FDDI

产品属性

机架高度: 3U

机架宽度: 4HP

附件类型: 前面板

包装数量: 1

正面表面处理: 涂漆

反面表面处理: 导电

引脚数: (3) 9

颜色代码: RAL 7035

深度 (D): 2.5mm

完成: 粉末涂层


高度 (H): 128.4mm

材料: 铝

产品类型: 前面板

宽度 (W): 19.98mm

Net Weight: 0.012kg

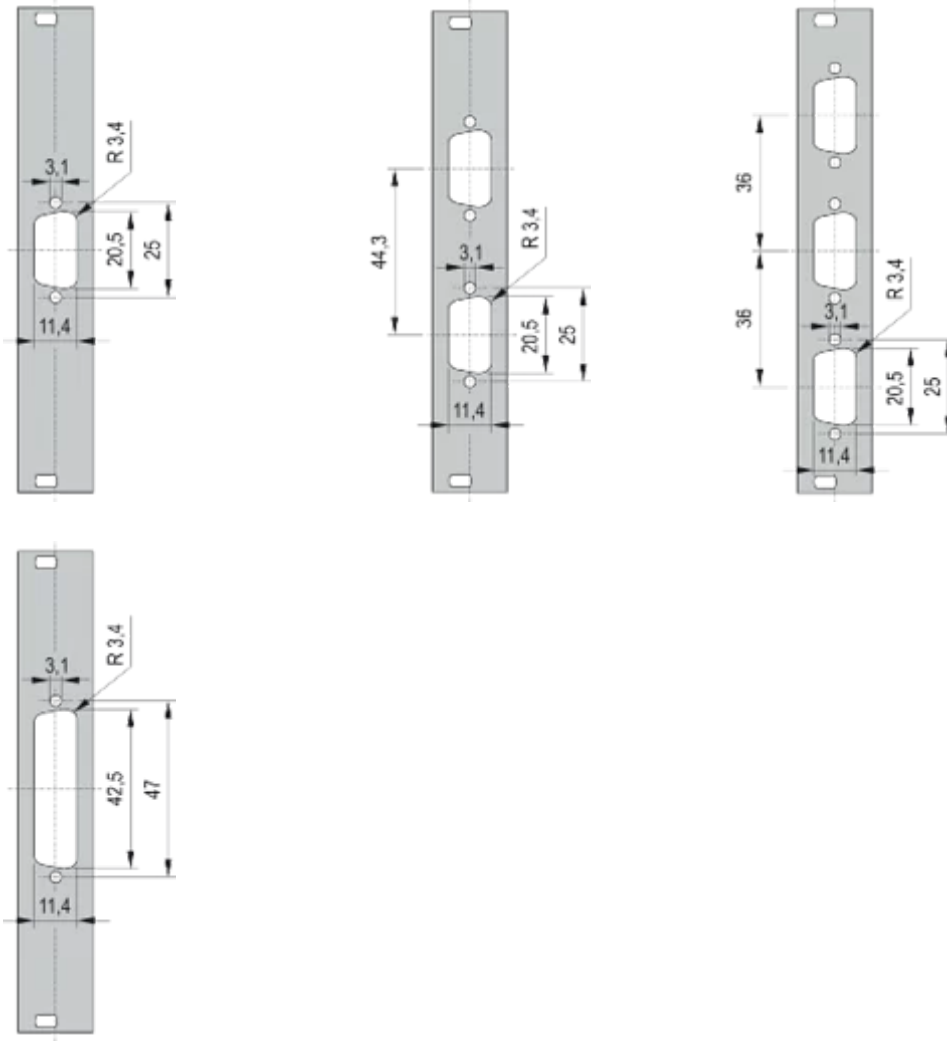

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE