


前面板，非屏蔽，适用于同轴连接器的开孔，2.5毫米，铝，前部经阳极氧化，后部导电

物料号

30118-355

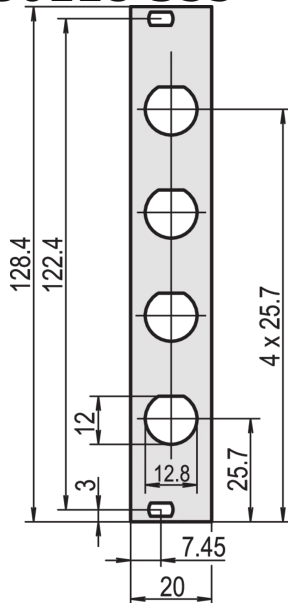

铝板，2.5mm，正面阳极氧化，反面导电，非屏蔽版本。

认证



功能

铝, 2.5 mm, 正面阳极氧化, 导电

3 U, 4 HP

产品属性

产品类型: 前面板

类型: 不带把手的前面板

附件类型: 前面板

安装: 正面螺钉安装

EMC 屏蔽: 否

材料: 铝

正面表面处理: 阳极氧化

反面表面处理: 导电

边缘处理: 否

机架高度: 3U

高度 (H): 128.4mm

机架宽度: 4HP

宽度 (W): 19.98mm

深度 (D): 2.5mm

符合: IEC 60297-3-101; IEEE 1101.1/10


包装数量: 1

完成: 阳极氧化; 钝化

其他产品详情

请单独订购紧固零件（螺钉套，凸缘螺钉）。

图

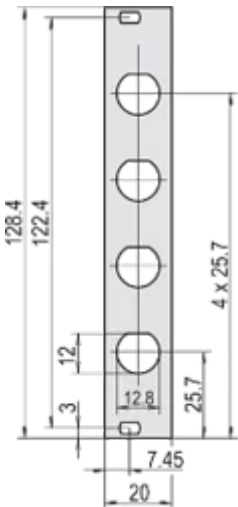

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE