


适合安装连接器的 Z 形轨道，EN 60603-2，40 HP

物料号

30822-045

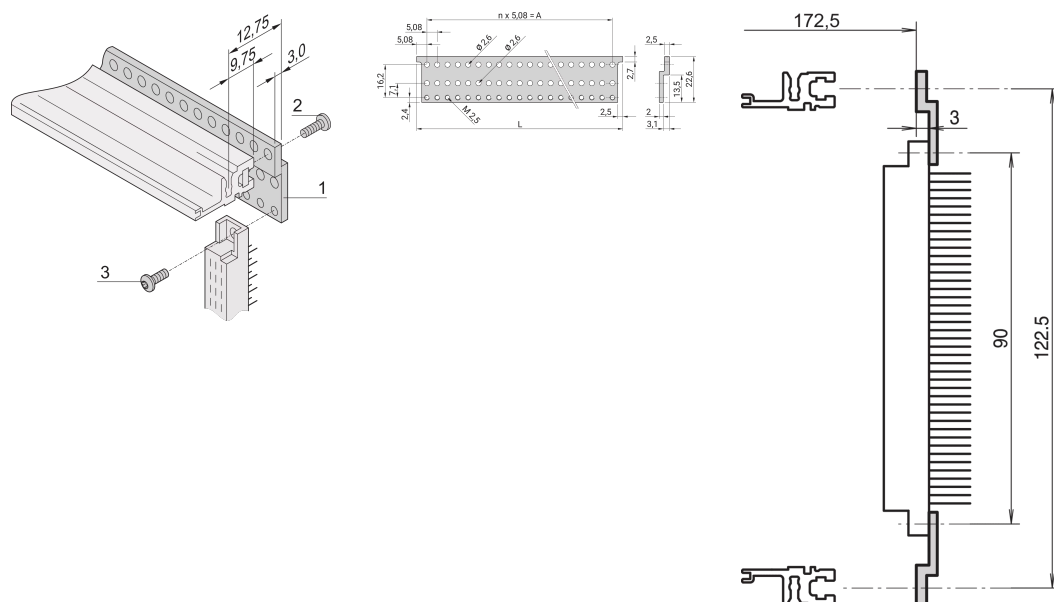

适用连接器的 Z 形轨道，符合 EN 60603-2 (DIN 41612) 标准。

认证



功能

铝挤压件, 阳极氧化

Z 型轨用螺栓固定在插箱上, 以安装连接器 (后水平轨道 ST 型), 插入螺纹插件, 绝缘条

适用于符合 EN 60603 - 2 (DIN 41612) 的连接器

产品属性

机架宽度: 40HP
包装数量: 1
完成: 阳极氧化
长度: 203.2mm
材料: 铝
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: Z 形导轨
搭配: 插箱; 仪器箱

其他产品详情

将 Z 形轨道安装在水平轨道上需要螺纹插件和内梅花盘头螺钉；请单独订购。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE