


适用组合安装的前面板替代产品，U 型，泡棉，6 U，2 HP，2.5 毫米，铝，前部经阳极氧化，后部导电

物料号

30849-140

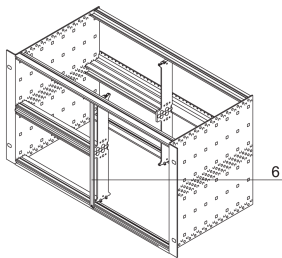

2 HP 宽的前面板可以覆盖开口插槽。U 形前面板可与泡棉 EMC 垫片结合使用。可用螺钉和垫圈固定。由于宽度为 2 HP，因此不能使用螺丝套。

认证



功能

U 形前面板 6 U, 2 HP, 铝, 2.5 mm

适用于泡棉 EMC 垫片

产品属性

产品类型: 前面板

附件类型: 前面板

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO

安装: 正面螺钉安装

EMC 屏蔽: 无 (可改装)

EMC 垫片类型: 织物
材料: 铝
正面表面处理: 阳极氧化
反面表面处理: 导电
边缘处理: 否
机架高度: 6U
高度: 261.8mm
机架宽度: 2HP
宽度: 9.8mm
深度: 2.5mm
符合: IEC 60297-3-101; IEEE 1101.1/10
包装数量: 1
完成: 阳极氧化; 钝化

其他产品详情

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE