


水平横梁，前端，L-KD 型，轻型，短缘，84 HP

物料号

34560-184

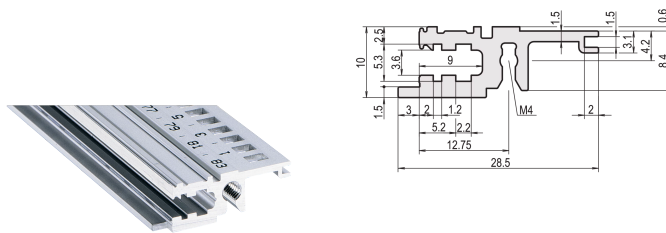

Combinations of horizontal rails and side panels

„+“ = can be combined, „-“ = combinations not recommended

	Side panel 1	Side panel 2	Side panel 3	Side panel 4
Horizontal rail 1	-	+	+	+
Horizontal rail 2	+	+	+	+
Horizontal rail 3	+	+	+	+
Horizontal rail 4	+	+	+	+
Horizontal rail 5	+	+	+	+
Horizontal rail 6	+	+	+	+
Horizontal rail 7	+	+	+	+
Horizontal rail 8	+	+	+	+

Side panel 1

带短缘的水平轨道为装配的前面板提供了一种洁净的设计。

认证



功能

前标准轨道

安装在顶部和底部

短缘 (L-KD)

< 28 HP 无丝印

铝挤压件, 阳极氧化, 接触表面导电

产品属性

机架宽度: 84HP

包装数量: 1

完成: 阳极氧化

长度: 431.8mm
材料: 铝
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: 水平横梁
类型: 轻型, KD
搭配: 插箱; 仪器箱

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE