
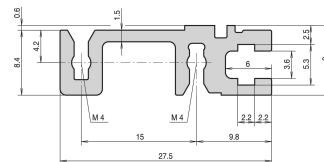


水平轨道，后部，L-ST 型，重型，标准，1000 mm

物料号

34560-501

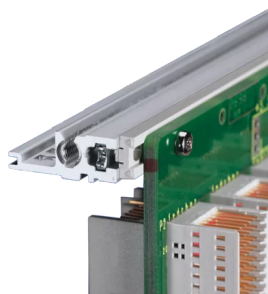

Combinations of horizontal rails and side panels

		„+“ = can be combined		„-“ = combination not recommended	
Rail	Standard L	-	+	+	+
	Standard H	+	+	+	+
Side panel	Standard L	+	+	-	-
	Standard H	+	+	-	-
		Standard L	Standard H	Standard L	Standard H

ST 型水平轨道可以非接触的方式装配背板。隔离通过绝缘条实现。

认证



功能

用于背板非接触安装，带绝缘条

符合高水平机械标准 (H-ST)

安装在插箱顶部和底部

< 28 HP 无印制

铝挤压件, 阳极氧化, 接触表面导电, 带 HP 标记

产品属性

机架宽度: 195HP
包装数量: 1
完成: 阳极氧化
长度: 1000mm
材料: 铝
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: 水平横梁
类型: 重型, ST
搭配: 插箱; 仪器箱
Net Weight: 0.304kg

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书, 或者向您的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE