


水平横梁, 后部, L-VT 型, 轻型, 28HP

物料号

34560-628

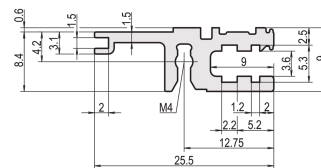

Combinations of horizontal rails and side panels

		"A" can be combined				"B" combination not recommended			
Horizontal rail	Standard 1.0	-	+	+	+	+	+	+	+
	Standard 1.5	+	+	+	+	+	+	+	+
	Standard 2.0	+	+	+	+	+	+	+	+
	Standard 2.5	+	+	+	+	+	+	+	+
Side panel	Light 1.0	+	+	+	+	+	+	+	+
	Standard 1.5	+	+	+	+	+	+	+	+
	Standard 2.0	+	+	+	+	+	+	+	+
	Standard 2.5	+	+	+	+	+	+	+	+

VT 型横梁, 可直接装配背板。

认证



功能

用于直接安装背板

嵌入式安装, 适用机械振动性能要求较低的环境 (L-VT)

安装在插槽顶部和底部

铝挤压件, 阳极氧化, 接触表面导电

产品属性

机架宽度: 28HP
包装数量: 1
完成: 阳极氧化
长度: 147.32mm
材料: 铝
产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
产品类型: 水平横梁
类型: 轻型, VT
搭配: 插箱; 仪器箱
Gross Weight: 0.042kg

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent

North America	Europe	Asia	Middle East & India
All locations	Straubenhardt, Germany	Shanghai, China	Dubai, United Arab
+1.763.422.2661	+49.7082.794.0	+86.21.2412.6943	Emirates
Chat with us:	Betschdorf, France	Qingdao, China	+971.4.378.1700
nvent.com/schroff	+33.3.88.90.64.90	+86.532.8771.6101	Bangalore, India
	Warsaw, Poland	Singapore	+91.80.6715.2001
	+48.22.209.98.35	+65.6768.5800	Istanbul, Turkey
	Assago, Italy	Shin-Yokohama, Japan	+90.216.250.7374
	+39.02.932.7141	+81.45.476.0271	Chat with us:
	Chat with us:	Chat with us:	nvent.com/schroff
	nvent.com/schroff	nvent.com/schroff	



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE