


导轨，多件式，中间件，塑料挤压件，长度 220 mm，宽度 2 mm，灰色，10 个

物料号

34564-892

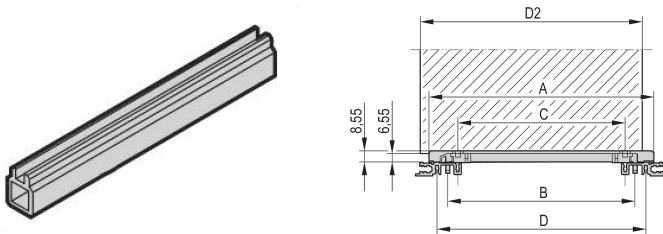

适用塑料或铝挤压件多件式导轨的导轨中间件。适合标准型、附件型、4.4" PCB 型导轨和带编码装置的尾端件。

认证



功能

中间型材，适合在 2 mm 宽的凹槽安装导轨

需要 2 个塑料尾端件；这些尾端件被推入中间型材两端

导轨可以卡入水平横梁（铝挤压件）或 1.5 mm 厚的板中

存储温度：-40 °C ... 130 °C

产品属性

材料: PVC

颜色: 灰色

包装数量: 1

板深度: 220mm

槽宽: 2

颜色代码: RAL 7035

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac

产品类型: 导轨

类型: 中段

搭配: 插箱; 仪器箱; 机箱

其他产品详情

可能按标准包装数量 (SPQ) 交货。以单件为单位定价。

一个导轨由 1 对头部件和 1 个型材件组成。

请注意，交货数量会按照声明的标准包装量执行（例如，5 件、10 件、50 件等）我们会将不符合规定的订购数量（例如 2 件）更改为下一个可执行的标准包装量发货。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE