


SCHUKO 插座条，8 个插座，19"，带开关

物料号

60110-206

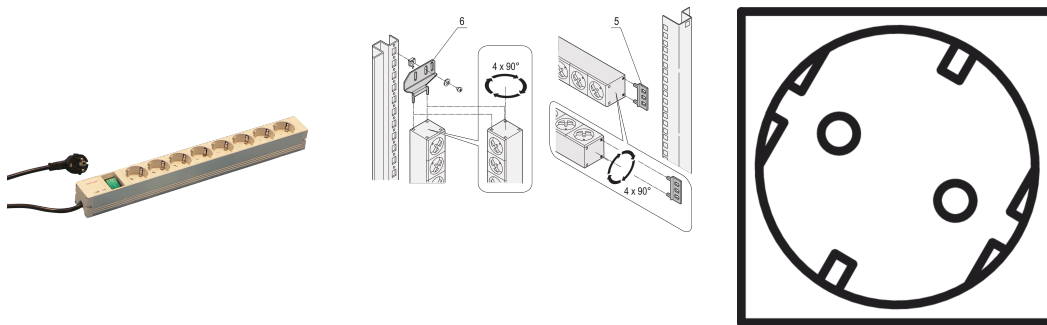

模块化、紧凑型 PDU，支持多种功能。利用 1U x 1U 铝机箱，PDU 可以轻松集成至带 SCHUKO 插座的机架中。

认证



功能

230 V, 16 A

水平或垂直安装

连接电缆 2 米，带 SCHUKO/UTE 插头

符合 DIN 57620 标准, VDE 0620

安装高度 1 U

带有 SCHUKO 插座的插排

安装时，插排可以向四个方向旋转（90°增量）

产品属性

插座类型: SCHUKO

插座数量: 8
开关插座: 是
交流电压: 230V
包装数量: 1
颜色: 灰色
深度: 44mm
完成: 阳极氧化
长度: 438.5mm
材料: 铝; 聚酰胺
产品类型: 插排
Net Weight: 0.865kg

其他产品详情

请单独订购垂直安装支架。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE