


SCHUKO 插座条, 3 相, 9 个插座

物料号

60110-219

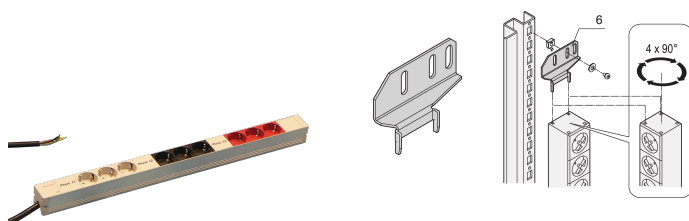

带 SCHUKO 插座和 3 相连接的模块化紧凑型 PDU。

认证



功能

符合 DIN 57620 标准

带有 SCHUKO 插座的插排, 3 相

连接电缆 2 米, 开放端带套管

3 相, 每相 16 A

安装时, 插排可以向四个方向旋转 (90°增量)

安装高度 1 U

垂直安装

产品属性

产品类型: 插排

插座类型: SCHUKO
插座数量: 9
颜色: 灰色; 黑色; 红色
开关插座: 否
长度: 608.5mm
交流电压: 230V
深度: 44mm
完成: 阳极氧化
材料: 铝; 聚酰胺
Net Weight: 1.65kg
包装数量: 1

其他产品详情

请单独订购垂直安装支架。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE