


导轨端件，标准类型，4.4 英寸 PCB 类型，槽宽 2 mm，红色

物料号

64560-057

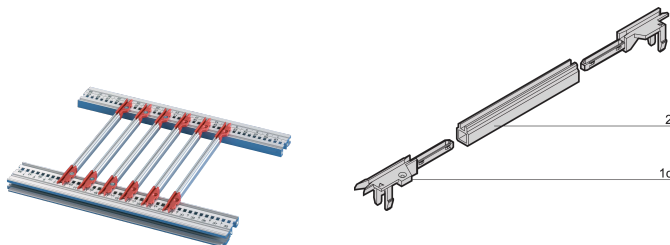

适用于单个多件式导轨的塑料尾端件，带塑料或挤压中间件。适用标准型、附件型或 4.4" PCB 型导轨。端部件可选配 ESD 夹，用来确保 PCB 和水平轨道之间的导电接触。适合 RatiopacPRO/-AIR、PropacPRO、CompacPRO 和 EuropacPRO。

认证



功能

适用于单个多件式导轨的导轨尾端件 (PBT)，带塑料或铝制挤压中间件。

导轨头可以夹入水平轨道（铝挤压件）或 1.5 mm 厚的板中

存储温度：0 °C ... +60 °C

储存温度：-40 °C ...130 °C

产品属性

产品类型: 导轨端件

产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO; MultipacPRO; Inpac
类型: 4.4" PCB
搭配: 插箱; 仪器箱; 机箱
包装数量: 1
包装单位: 对
Gross Weight: 0.003kg
材料: 聚对苯二甲酸丁二醇酯

其他产品详情

以多个标准包装的形式交货。以单件为单位定价。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE