


适于背板的 EuropacPro 19 英寸插箱套件, 灯, 非屏蔽型

用于背板安装的非 EMC 屏蔽型插箱, 轻型款。

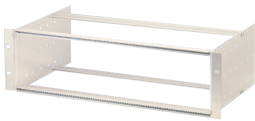

认证



功能

插箱带有 L 型（“轻型”）侧面板，并集成 19" 支架

“轻”型水平横梁

铝结构

含用于安装背板的后水平轨道，带绝缘条

器件负载高达 7.5 千克

扁平包装，节省空间

内部和外部尺寸符合：IEC 60297-3-100, -101, IEEE 1101.1

提供改造，如开孔、各种表面或尺寸

技术参数

材料: 铝

完成: 阳极氧化; 钝化

EMC 屏蔽: 否

产品类型: 插箱/机箱

Table 1/2

物料号	机架高度	深度	包装数量	用于安装	板深度	包含手柄
24564-131	3U	175mm	1	背板	160mm	否
24564-132	3U	235mm	1	背板	160mm, 220mm	否
24564-133	3U	295mm	1	背板	160mm, 220mm, 280mm	否
24564-431	6U	175mm	1	背板	160mm	否
24564-432	6U	235mm	1	背板	160mm, 220mm	否
24564-433	6U	295mm	1	背板	160mm, 220mm, 280mm	否

Table 2/2

物料号	安装	符合	机架宽度	静态负载	快速发货
24564-131	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No
24564-132	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No
24564-133	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No
24564-431	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No
24564-432	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No

物料号	安装	符合	机架宽度	静态负载	快速发货
24564-433	机架	IEC 60297-3-100, IEC 60297-3-101, IEEE 1101.1	84HP	7.5kg	No

其他产品详情

插箱没有屏蔽功能，可改装为达到 IP 20 防护等级

支持个性化配置: 支持较大范围高度，宽度和深度定制；根据不同应用可选多种规格导轨,内部附件和安装材料。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE