


EuropacPRO Guide Rails to Accomodate Conduction Cooled Assemblies

该转接件是插箱和传导散热组件 (CCA) 之间的接口。

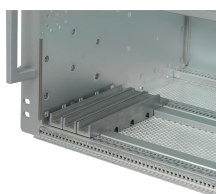

认证



功能

用于将传导散热组件 (CCA) 固定在插箱中的转接件

技术参数

- 材料: 铝
- 搭配: 插箱; 仪器箱
- 产品系列: EuropacPRO; RatiopacPRO; RatiopacPRO AIR; CompacPRO; PropacPRO
- 产品类型: 导轨

Table 1/2

物料号	类型	包装数量	槽宽	完成	长度	包装单位
24566-004	导冷总成 VPX	2	13.3	钝化	160mm	对

物料号	类型	包装数量	槽宽	完成	长度	包装单位
24566-005	导冷总成 CompactPCI	2	13.3	钝化	160mm	对

Table 2/2	
物料号	快速发货
24566-004	No
24566-005	No

其他产品详情

适用于重型和加固型水平轨道。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America	Europe	Asia	Middle East & India
All locations +1.763.422.2661 Chat with us: nvent.com/schroff	Straubenhardt, Germany +49.7082.794.0 Betschdorf, France +33.3.88.90.64.90 Warsaw, Poland +48.22.209.98.35 Assago, Italy +39.02.932.7141 Chat with us: nvent.com/schroff	Shanghai, China +86.21.2412.6943 Qingdao, China +86.532.8771.6101 Singapore +65.6768.5800 Shin-Yokohama, Japan +81.45.476.0271 Chat with us: nvent.com/schroff	Dubai, United Arab Emirates +971.4.378.1700 Bangalore, India +91.80.6715.2001 Istanbul, Turkey +90.216.250.7374 Chat with us: nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE