


带盖板时使用的 EuropacPRO 安装板

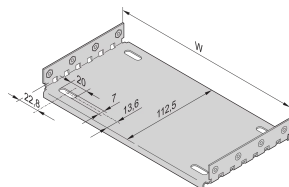

带盖板时使用的安装板，适用于安装和固定重型组件。全宽安装板（与插箱或系统机箱一样宽）可固定至侧面板。非全宽安装板可通过装配条固定至侧面板和水平横梁。

4,4”型和加强型导轨不能与安装板组合使用。适用轻型（L型）水平横梁凹槽的顶盖/底盖不能与安装板组合使用。

认证



功能

用于安装和固定重型组件

安装板, 全宽: 安装板的宽度与插箱/系统机箱一样宽, 并固定在侧面板上

导轨可安装在第一和最后一个槽位置

除安装板外, 还可以将 EMC 盖板安装到插箱

不能使用4.4型和“加固”型导轨

导轨可固定在首个或最后一个槽中

技术参数

材料:	铝
产品系列:	EuropacPRO
产品类型:	安装板
搭配:	插箱

Table 1/1

物料号	机架宽度	包装数量	深度	宽度	认证	快速发货
-----	------	------	----	----	----	------

34563-004	84HP	1	112.5mm	431.35mm	RoHS	No
34563-019	63HP	1	172.5mm	324.67mm	RoHS	No
34563-014	42HP	1	172.5mm	217.99mm	RoHS	No
34563-009	28HP	1	172.5mm	146.88mm	RoHS	No
34563-003	63HP	1	112.5mm	324.67mm	RoHS	No
34563-002	42HP	1	112.5mm	217.99mm	RoHS	No
34563-001	28HP	1	112.5mm	146.88mm	RoHS	No
34563-024	84HP	1	172.5mm	431.35mm	RoHS	No
34563-044	84HP	1	412.5mm	431.35mm		No
34563-042	84HP	1	352.5mm	431.35mm		No
34563-028	84HP	1	292.5mm	431.35mm		No
34563-026	84HP	1	232.5mm	431.35mm		No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE