


Eurorack 滑轨, 25 公斤

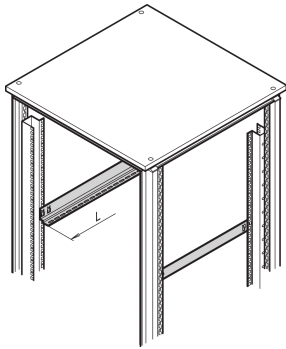

Eurorack L型滑动安装轨，承载能力为 25 kg，适合安装在机柜立柱或 19" 面板/角轨安装件上。滑轨可以支撑重型 19" 机箱的机架。

认证



功能

碳钢, 1.5 mm, 覆铝锌表面

静态承载能力 25 千克/每对

重型 19" 机箱支撑架

适用于在 19" 面板/角轨安装件上装配

宽支撑表面

可以 1 U 增量安装

技术参数

静态负载: 25kg

产品类型: 滑轨

材料: 钢

Table 1/1

物料号	深度	长度	包装数量	完成	快速发货
22127-094	600mm	420mm	2	镀锌铝	No
25127-575	800mm	512mm	2	镀锌铝	No
22127-095	800mm	620mm	2	镀锌铝	No
22127-096	900mm	717mm	2	镀锌铝	No
21127-197	600mm	420mm	10	镀锌铝	No
21127-198	800mm	620mm	10	镀锌铝	No
21127-199	900mm	720mm	10	镀锌铝	No

其他产品详情

服务器的标准距离 d=740mm。组装时需要4件面板/滑动底座（请单独订购，请参阅面板/滑动底座）。

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations

+1.763.422.2661

Chat with us:

nvent.com/schroff

Europe

Straubenhardt, Germany

+49.7082.794.0

Betschdorf, France

+33.3.88.90.64.90

Warsaw, Poland

+48.22.209.98.35

Assago, Italy

+39.02.932.7141

Chat with us:

nvent.com/schroff

Asia

Shanghai, China

+86.21.2412.6943

Qingdao, China

+86.532.8771.6101

Singapore

+65.6768.5800

Shin-Yokohama, Japan

+81.45.476.0271

Chat with us:

nvent.com/schroff

Middle East & India

Dubai, United Arab

Emirates

+971.4.378.1700

Bangalore, India

+91.80.6715.2001

Istanbul, Turkey

+90.216.250.7374

Chat with us:

nvent.com/schroff



我们强大的品牌组合:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE