


Eurorack 通用型框架

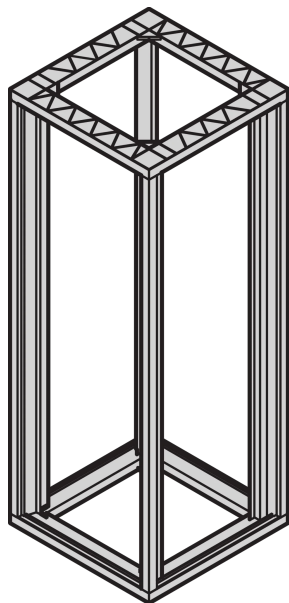

螺钉固定，铝压铸框架，铝挤压件支柱。

认证



功能

表面：RAL 7021

螺钉固定, 铝压铸框架, 支柱铝挤压件

可应要求提供其他尺寸

19" 平面, 深度可调, 以 25 mm为增量, 可使用埋深构件和 19" 面板/滑轨安装件装配

技术参数

静态负载: 400kg

材料: 铝

产品类型： 机柜/机架框架

Table 1/2						
物料号	机架高度	高度	宽度	深度	包装数量	颜色
22117-787	38U	1798mm	600mm	900mm	1	暗灰色
22117-791	43U	2020mm	600mm	800mm	1	暗灰色
22117-792	43U	2020mm	600mm	900mm	1	暗灰色

Table 2/2						
物料号	颜色代码	完成	框架材料	类型	认证	快速发货
22117-787	RAL 7021	粉末涂层	铝	通用型	RoHS	No
22117-791	RAL 7021	粉末涂层	铝	通用型	RoHS	No
22117-792	RAL 7021	粉末涂层	铝	通用型		No

警告

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE