


Fan Control Module FCM3

Management Module for Fan Control and Voltage Monitoring.

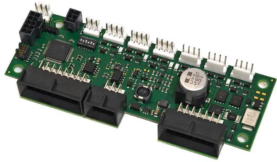

认证



功能

风扇控制模块 (FCM3) 是用于 12 或 24 V 风扇的独立风扇控制器

可监控和控制多达 6 个风扇

可监控多达 6 个温度传感器的信号

监控 3.3 V、, 5 V, 12/24V 和 -12V 电压

FCM3 电源电压: 12 至 24V

可控制过温状态 LED 灯, 风扇故障, 3.3 V, 5 V, 12/24V 和 -12V

当风扇出现过热情况或故障时, 其他风扇将设置为全速

可通过 SMBus 接口查询状态信息

适用于带 PWM 的 4 线风扇

技术参数

Table 1/1

物料号	搭配	深度	高度	包装数量	宽度	快速发货
23207-170	CompactPCI 系统	119mm	15mm	1	49mm	No

物料号	搭配	深度	高度	包装数量	宽度	快速发货
23207-172	CompactPCI 系统	119mm	15mm	1	40mm	No

警告

应仅根据 nVent 的产品说明书与培训材料安装并使用 nVent 的产品。可访问 www.nvent.com 获取说明书，或者向您的 nVent 客服代表索取。错误安装、使用不当、滥用或未能完全遵守 nVent 的说明与警告，可能会造成产品故障、财产损失、严重的人身伤害及死亡和/或使得保修服务无效。

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab
Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:
nvent.com/schroff



我们强大的品牌组合:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE